


Female connector
with straight solder pins
Contact spacing .098"

Directive 2002/95/EC
„RoHS“
Compliant

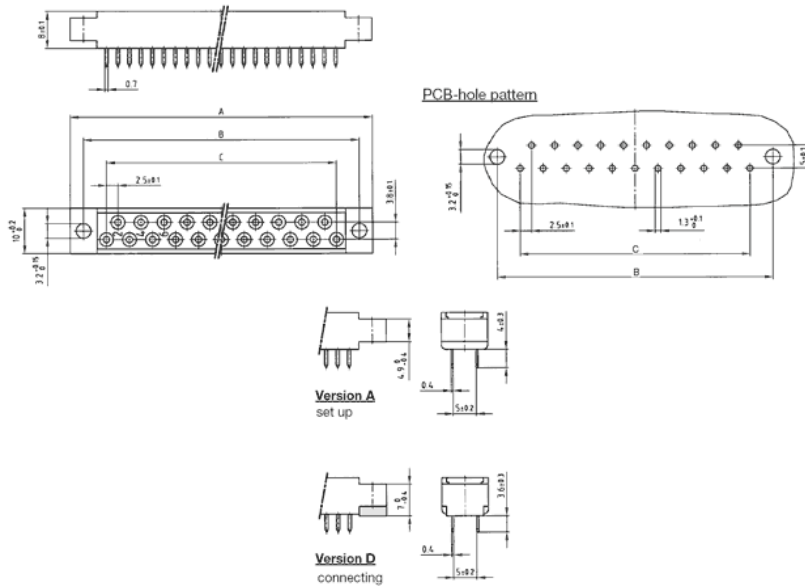

No. of Pos.	A ± 0.3	B ± 0.1	C ± 0.1
13	45,8	40,0	12 x 2,5 = 30
21	65,8	60,0	20 x 2,5 = 50
31	90,8	85,0	30 x 2,5 = 75

Part Numbers

No. of Pos.	Plastic part	hard-silver-plated	Quality class 3	Quality class 2	Quality class 1
13	version A	102 E 10049 X	102 A 10049 X	102 B 10049 X	102 C 10049 X
13	version D	102 E 10059 X	102 A 10059 X	102 B 10059 X	102 C 10059 X
21	version A	102 E 10069 X	102 A 10069 X	102 B 10069 X	102 C 10069 X
21	version D	102 E 10079 X	102 A 10079 X	102 B 10079 X	102 C 10079 X
31	version A	102 E 10089 X	102 A 10089 X	102 B 10089 X	102 C 10089 X
31	version D	102 E 10099 X	102 A 10099 X	102 B 10099 X	102 C 10099 X