


Sockets

KD 10

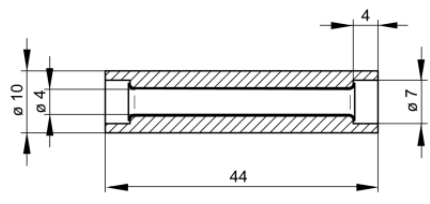

Product	KD 10
description	Insulated coupling with a tin-plated brass tube for two 4 mm diameter plugs.
operating instruction	BA407
article-no. / *colour	9301091xx  00 black  01 red Ni
drawing	
	
technical data	
connection	unsprung socket 4 mm
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	10 A
material socket	brass, tin plated
housing material	PS
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 14.12.2022

stand: 14.12.2022