


Sockets

MBU 1

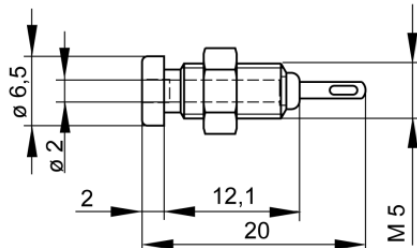

Product	MBU 1
description	2 mm diameter bright metal miniature socket. Brass nickel-plated socket body, tin-plated copper beryllium contact spring, with solder connection. Suitable for installation in equipment chassis and switch panels up to a maximum wall thickness of 8 mm.
operating instruction	BA205
Articlenummer	930312000 Sn
drawing	
	
technical data	
connection	solder connection
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	6 A
material socket	contact spring: copper - beryllium

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains
stand: 21.06.2022

stand: 21.06.2022

2 mm system