


Sockets

PKN 10 B

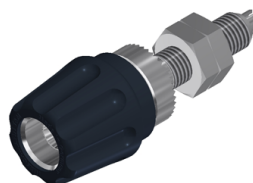

Product	PKN 10 B
description	Pole terminal with claw edge and captive insulated head. 6 mm diameter nickel-plated brass threaded bolt with 2.6 mm diameter transverse hole. For non-rotating installation in equipment chassis and switchpanels.
operating instruction	BA403
article-no. / *colour	9301171xx ● 00 black ● 01 red ● 02 blue ● 03 yellow ● 04 green Ni
drawing	
technical data	
connection	M6 thread, solder connection
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	63 A
material socket	brass, nickel plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022