


Plugs

VSB 20

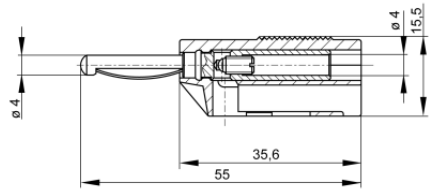

Product	VSB 20
description	Fully mating connector with cable gland and 4 mm socket for onward connection capability. Screw connection up to maximum cable cross-section of 2.5 mm ² and external diameter of 4 mm. Nickel-plated brass contact material.
operating instruction	BA411
article-no. / *colour	9304351xx  00 black  01 red  02 blue  03 yellow  04 green  06 gray  07 white Ni
drawing	
	
technical data	
connection	screw terminal
rated voltage	30 VAC / 60 VDC
rated current (consider derating curve)	30 A
material plug	brass, nickel plated
housing material	PP
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
 stand: 01.06.2023

stand: 01.06.2023

4 mm system