


Sockets

BU 10 Au

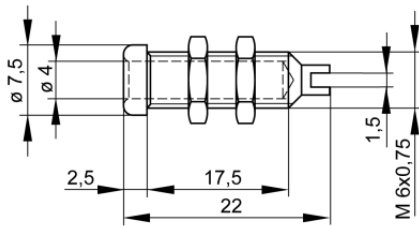

Product	BU 10 Au
description	Bright metal 4 mm diameter gold-plated brass socket with solder connection and M6 thread. For installation in equipment chassis and switch panels till 11 mm wall thickness.
operating instruction	BA403
Articlenummer	930147700 Au
drawing	
	
technical data	
connection	M6 thread, solder connection
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	16 A
material socket	brass, gold plated
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022

4 mm system