


Sockets

SEP 2620 F6,3

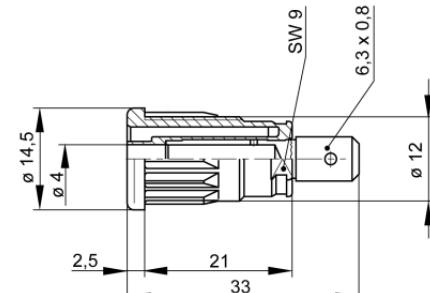

Product	SEP 2620 F6,3
description	Safety press-in socket, 4 mm diameter, contact-protected, with 6.3 x 0.8 tab connector complying with DIN 46 244, gold-plated brass. For rapid installation into switchpanels with wall thicknesses between 1-10 mm. Installation hole: $\varnothing 12.2 \pm 0.1$ mm Entry chamfer: $0.5 \times 45^\circ$
operating instruction	BA454
article-no. / *colour	9723621xx  00 black  01 red  02 blue  03 yellow  04 green  88 yellow green Au
drawing	
	
technical data	
connection	flat connector 6.3 x 0.8 mm
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	32 A
material socket	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-40 °C to +80 °C

4 mm safety system

inflammability class acc. to UL 94 (only valid for basic material of housing)	V-2
--	-----

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges
 stand: 21.06.2022

stand: 21.06.2022