

# 1/4" Plugs

## NYS203

### Product

Connector Type Plug

Gender male

### Electrical

Contact resistance < 10 mΩ

Dielectric strength 0,5 kVdc

Rated current per contact depends on mated connector A

### Mechanical

Cable O.D. ≤ 6 mm

Lifetime 5000 mating cycles

Wire size 24 AWG

### Material

Bushing Steel sp.

Contact plating 2 μm Ni

Contacts Brass (CuZn39Pb3)

Insert Polyamide (PA 6.6 30 % GR)


Shell ABS

Strain relief CRIMP type snce plated

### Environmental

Solderability Complies with IEC 68-2-20

Temperature range -20 °C to +70 °C

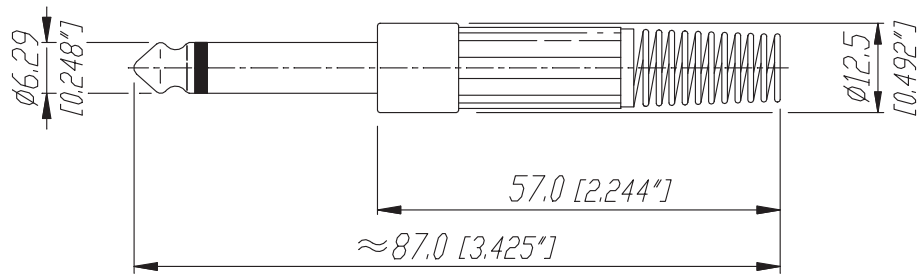

Ind.	Aenderung	Datum	Name	Werkstoff:	Massstab:	Datum	Name
				*)Lieferant darf ohne Ruecksprache nicht geaendert werden	1:1	Gezeichnet	29.01.01 Battlogg
			Zeichnung urheberrechtlich geschuetzt (DIN 34) (C)			Gepueft	
			Benennung:	1/4" Phone Plugs NYS 203		Gesehen	
						Ersetzt durch:	Blatt
					Ersatz fuer:	von Blatt	
				REAN		Zeichn. Nr.	3102 ST 22 16