
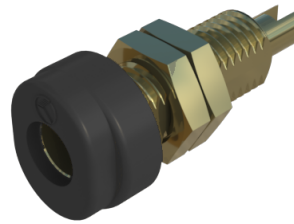


Sockets

BUG 10 Au

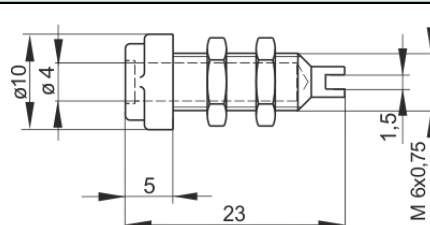

Product	BUG 10 Au
description	Socket with oval insulated head, Ø 4 mm gold-plated zinc die-cast socket, with M6 thread and solder connection. For installation in equipment chassis and switch panels till 8mm wall thickness.
operating instruction	BA403
article-no. / *colour	9301757xx  00 black  01 red  02 blue  03 yellow  04 green  07 white Au
drawing	
	
technical data	
connection	M6 thread, solder connection
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	16 A
material socket	SKS_ZINKDRUCKGUSS-VERZINNT
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +85 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains
stand: 24.08.2022

stand: 24.08.2022