

Audio

## 1/4" Plugs

[back](#)

### NYS228BG

#### Product

Connector Type Plug

Gender male

#### Electrical

Contact resistance < 10 mΩ

Dielectric strength 0,5 kVdc

Rated current per contact depends on mated connector A

#### Mechanical

Cable O.D. ≤ 6 mm

Lifetime 5000 mating cycles

Wire size 24 AWG

#### Material

Contact plating 0.2 μm Au

Contacts Brass (CuZn39Pb3)

Insert Polyamide (PA 6.6 30 % GR)


Shell Zinc diecast (ZnAl4Cu1) Black

Strain relief CRIMP type snce plated

#### Environmental

Solderability Complies with IEC 68-2-20

Temperature range -20 °C to +70 °C

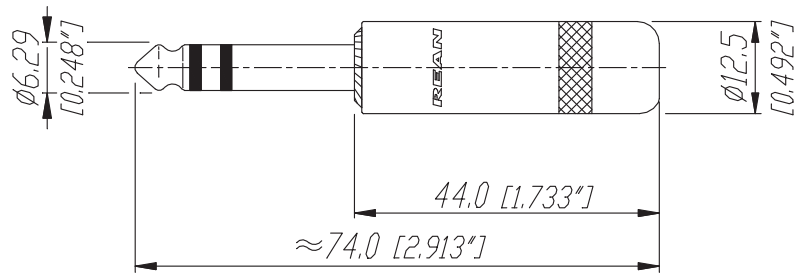

Ind.	Aenderung	Datum	Name	Werkstoff:	Massstab:	Datum	Name	
				*Lieferant darf ohne Ruecksprache nicht geaendert werden	1:1	Gezeichnet	29.01.01	Battlogg
				Zeichnung urheberrechtlich geschuetzt (DIN 34) (C)		Geprueft		
				Benennung: 1/4" Phone Plugs NYS 228BG		Gesehen		
						Ersetzt durch:		Blatt
						Ersatz fuer:		von Blatt
				<b>REAN</b>		Zeichn. Nr.	3102 ST 22 21	