


Sockets

KUN 10

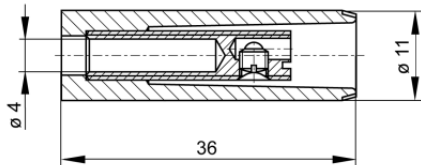

Product	KUN 10
description	Insulated coupling for a 4 mm diameter plug and screw connection up to cable cross-section of 1.5 mm ² . Tin-plated brass socket. The socket is screwed into the insulated handle.
operating instruction	BA404
article-no. / *colour	9301891xx  00 black  01 red Sn
drawing	
	
technical data	
connection	screw terminal
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	16 A
material socket	brass, tin plated
housing material	PS
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains
stand: 21.06.2022

stand: 21.06.2022

4 mm system