
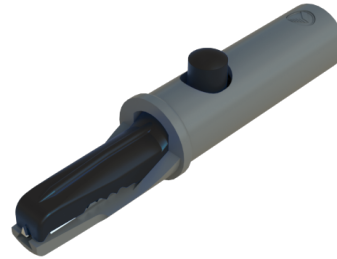


Crocodile clips

AK 10

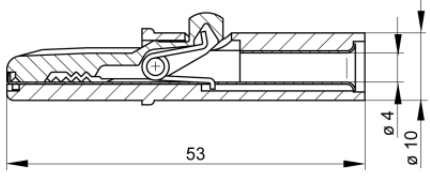

Product	AK 10
description	Insulated alligator clip. Clamping range up to 6 mm bolt diameter. Fine wire section for very thin wires. Only the lower part of the clip has a tin-plated, brass contact insert. 4 mm diameter socket connection.
operating instruction	BA420
article-no. / *colour	9301261xx ● 00 black ● 01 red ● 02 blue ● 03 yellow ● 04 green Sn
drawing	
	
technical data	
connection	unsprung socket 4 mm
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	6 A
material socket	brass, tin plated
housing material	PS
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +60 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB
clamping range	6 mm

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains

stand: 21.06.2022

stand: 21.06.2022