


Date: 23.04.2012

RRJ_USB_SW

Technical Data

Type reference:	RRJ_USB_SW Front side in black
USB connector:	Type A
USB jack:	Type A
USB cable:	USB-2.0 Length 0.6m
Protection type:	IP65
Mounting diameter:	22.3mm
Storage temperature:	-25°C ... +80°C
Operating temperature max.:	-20°C ... +60°C

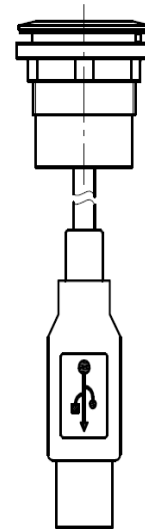

- Subject to alterations -