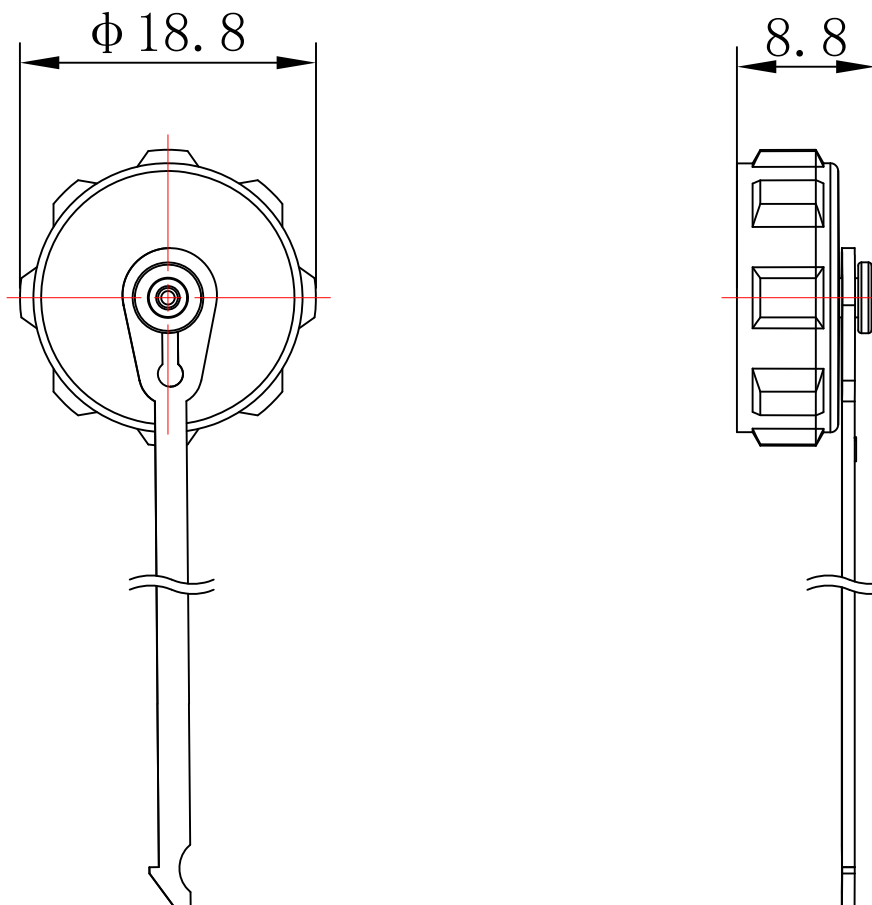


**技术参数 Specs:**

极数 No. of pins: /

额定电流 Rated current: /

接触直径 Contact diameter: /

工作电压 Rated voltage: /

耐压 Tested voltage: /

接触电阻 Contact resistance: /

绝缘电阻 Insulation resistance: /

线规 Wire size(mm²/AWG): /

电缆外径 Cable OD(mm): /

接插方式 Coupling: 螺纹连接 Threaded

外壳材料 Shell material: 热塑性塑料PA66 防火等级: V-0 Nylon66, fire resistance: V-0

绝缘体 Insert material: /

接触件材料 Contact material: /

接线方式 Termination: /

接插次数 Mating cycle: /

工作温度 Working temperature: /

盐雾等级 Salt spray level: /

防护等级 IP rating: IP68(连接后after connection)

设计标准 Design standard: /

特制内容 Custom: 产品符合REACH

普通公差 Normal tolerance: 长度 Length 角度 Angle X. ± 0.5 .X $\pm 1^\circ$.X ± 0.3 X. $\pm 0.5^\circ$.XX ± 0.15		签 名 Signature	日期 Date	广东威浦电器有限公司 Guangdong Weipu Electric Appliance Co.,LTD						
设计 Design		吴镇华	2025-09-12	名称 Description	型号 PartNumber	编号 Code	版本 version			
审核 Review		陈带兴	2025-09-12	SP13型插座护盖组件 (RE)	SP13-GZ-RE	10203903240	A/0			
批准 Approve		吴镇华	2025-09-12							
视图 View 										
GB/T 14486-MT4										