

## Steckzungen

Masse im Steckbereich  
DIN 46342, Teil 1




## Languettes

Dimensions zone d'emboîtement selon  
DIN 46342, partie 1

## Tabs

Dimensions in the tab sector  
DIN 46342, part 1


2,8 mm
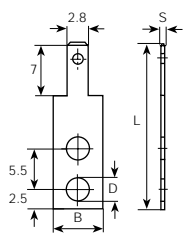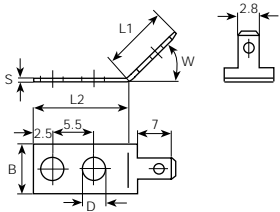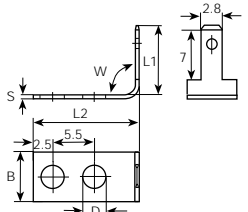
|  | øD<br>mm | B<br>mm | L<br>mm  | S<br>mm  |     |         | Werkstoff<br>Matière<br>Material | Stand-<br>Packg. | Artikel-Nr.<br>Numéro d'article<br>Part-No. |
|--|----------|---------|----------|----------|-----|---------|----------------------------------|------------------|---|
|   | 3        | 6.5     | 21.5     | 0.5      |     |         | MS                               | 1000             | 3778T05.6( )                                |
|  | 3        | 6.5     | 21.5     | 0.8      |     |         | MS                               | 1000             | 3778T08.6( )                                |
|  | 3        | 5       | 19       | 0.5      |     |         | MS                               | 1000             | 3778U05.6( )                                |
|  | 3        | 5       | 19       | 0.8      |     |         | MS                               | 1000             | 3778U08.6( )                                |
| <div style="background-color: black; color: white; padding: 2px; display: inline-block; margin-bottom: 5px;">45°</div>   | øD<br>mm | B<br>mm | L1<br>mm | L2<br>mm | W   | S<br>mm | Werkstoff<br>Matière<br>Material | Stand-<br>Packg. | Artikel-Nr.<br>Numéro d'article<br>Part-No. |
|  | 3        | 6.5     | 8.7      | 12.5     | 45° | 0.5     | MS                               | 1000             | 3778T4505.6( )                              |
|  | 3        | 6.5     | 8.7      | 12.5     | 45° | 0.8     | MS                               | 1000             | 3778T4508.6( )                              |
|  | 3        | 5       | 8.2      | 10.5     | 45° | 0.5     | MS                               | 1000             | 3778U4505.6( )                              |
|  | 3        | 5       | 8.2      | 10.5     | 45° | 0.8     | MS                               | 1000             | 3778U4508.6( )                              |
| <div style="background-color: black; color: white; padding: 2px; display: inline-block; margin-bottom: 5px;">90°</div>  | øD<br>mm | B<br>mm | L1<br>mm | L2<br>mm | W   | S<br>mm | Werkstoff<br>Matière<br>Material | Stand-<br>Packg. | Artikel-Nr.<br>Numéro d'article<br>Part-No. |
|  | 3        | 6.5     | 8.7      | 12.5     | 90° | 0.5     | MS                               | 1000             | 3778T9005.6( )                              |
|  | 3        | 6.5     | 8.7      | 12.5     | 90° | 0.8     | MS                               | 1000             | 3778T9008.6( )                              |
|  | 3        | 5       | 8.2      | 10.5     | 90° | 0.5     | MS                               | 1000             | 3778U9005.6( )                              |
|  | 3        | 5       | 8.2      | 10.5     | 90° | 0.8     | MS                               | 1000             | 3778U9008.6( )                              |

## Steckverteiler

Masse im Steckbereich  
DIN 46342, Teil 1

für Steckzungen  
pour languettes - 2,8x0,5  
for tabs

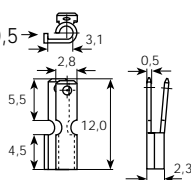


Artikel-Nr.  
Numéro d'article  
Part-No. → 378105.6( ) MS

2.8x0.5 / 2.8x0.5  
1000

Stand-Packg.

## Raccords mixtes

Dimensions zone d'emboîtement selon  
DIN 46342, partie 1

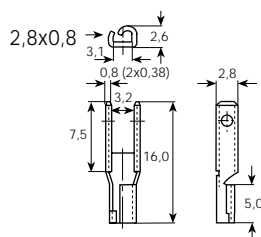


378108.6( ) MS

2.8x0.8 / 2.8x0.8  
1000

## Multi-connectors

Dimensions in the tab sector  
DIN 46342, part 1

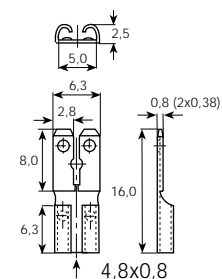

3829C.67 MS sn

siehe Seite  
voir page  
see page | 336