
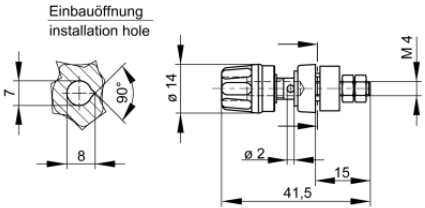


## Sockets

### PKI 10 A



Product	PKI 10 A
description	Pole terminal with claw edge and captive insulated head and insulated ring. 4 mm diameter nickel-plated brass threaded bolt with 2 mm diameter transverse hole. For insulated, non-rotating installation in equipment chassis and switchpanels with a wall thickness up to 2 mm.
operating instruction	BA402
article-no. / *colour	9301031xx  <span style="border: 1px solid black; padding: 2px;">Ni</span>
drawing	
technical data	
connection	M4 thread
rated voltage <sup>(1)</sup>	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O <sup>(3)</sup>
rated current <sup>(1)</sup> (consider derating curve)	35 A
material socket	brass, nickel plated
housing material	PF
temperature range acc. To IEC61010 <sup>(2)</sup>	-25 °C to +100 °C
standard	IEC 61010

4 mm system

<sup>(1)</sup> for normal environmental conditions -5°C to +40°C

<sup>(2)</sup> contact the manufacturer for applications at deviating temperature ranges

<sup>(3)</sup> without rated measurement category, for other circuits that are not directly connected to mains

stand: 03.09.2018