


Sockets

PKI 100

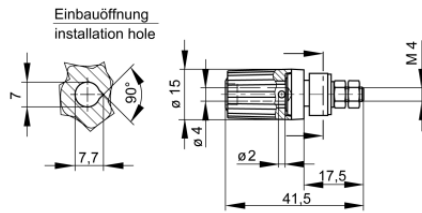

Product	PKI 100
description	Pole terminal with captive insulated head, which is held under constant pressure against the insulated rings by a spring. 4 mm diameter nickel-plated, brass threaded bolt with 2 mm diameter transverse hole. For non-rotating installation in switchpanels and equipment chassis with wall thickness up to 3.5 mm.
operating instruction	BA402
article-no. / *colour	9307571xx ● 00 black ● 01 red ● 02 blue ● 03 yellow ● 04 green ● 88 yellow green Ni
drawing	
	 Einbauöffnung installation hole 7 7.7 90° 15 4 2 17.5 41.5 M 4
technical data	
connection	M4 thread
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	35 A
material socket	brass, nickel plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +100 °C
inflammability class acc. to UL 94 (only valid for basic material of housing)	V-2

4 mm system

⁽¹⁾ contact the manufacturer for applications at deviating temperature ranges

⁽²⁾ without rated measurement category, for other circuits that are not directly connected to mains
stand: 21.06.2022

stand: 21.06.2022