

MiniDIN-Steckverbinder, Leiterplattenmontage (180°)

MiniDIN-connector, PCB mounting top entry (180°)



Isolierkörper
PBT, 30% Glasfaser verstärkt

Strombelastbarkeit
2A DC

Nennspannung
12V DC

Kontaktwiderstand
30mΩ max

Durchschlagsspannung
500V AC / 1 Minute

Isolationswiderstand
500MΩ min. bei 500V DC

Temperaturbereich
-25°C - +85°C

Insulator
PBT, 30% glasfiber reinforced

Current rating
2A DC


Current voltage
12V DC

Contact resistance
30mΩ max.

Dielectric strength
500V DC / 1 minute

Insulation resisatance
500MΩ min. at 500V DC

Operating temperature
-25°C - +85°C

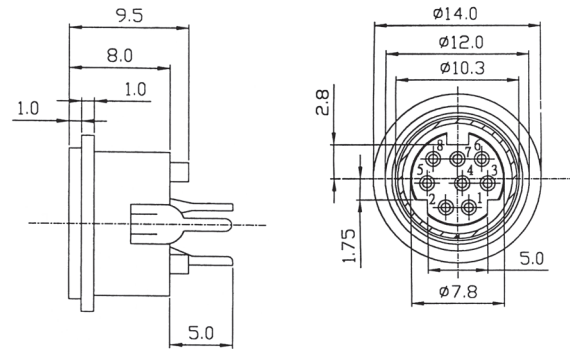

Bestellcode : **A - DIO - TOP / x**
Ordercode :

Bitte „x“ durch die unten geeignete Option ersetzen
Please replace „x“ with appropriate option listed below

1.

1. No. of contacts
03, 04, 05, 06, 08

Polzahl
03, 04, 05, 06, 08

D-Sub / Hoods
Centronics

Multiflex

Modular

USB

Switches

Powercords
Powersockets

MiniDIN

DIN4161x
Hardmetric

Sockets + Strips
Jumper