


Housing design H-B. The industry standard.

Product Description

Ideal for many applications due to a wide range of housings and inserts

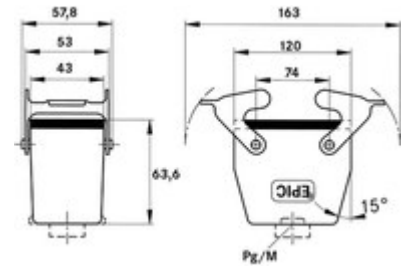

Application range

- Plant engineering
- Light & sound technology
- Plastics industry

Benefits

- Ideal for many applications due to a wide range of housings and inserts

Product features

- Cable coupler hood, low version
- Dual levers
- Straight cable entry
- Versions with / without neck



Technical Data

Material

Housing: powder-coated aluminium alloy, grey

Lever: zinc-plated steel Sealing: NBR

Protection rating

IP 65 (latched)

Temperature range

-40 °C to +100 °C, short-term up to +125 °C

Article List

| Part number | Article | M | PG | Neck | Pieces / PU |
|--|----------------|----|----|------|-------------|
| H-B housing: cable coupler hood (straight cable entry, double lever) | | | | | |
| 10127000 | H-B 24 TBF 21 | | 21 | yes | 5 |
| 10117000 | H-B 24 TBF 29 | | 29 | yes | 5 |
| 19127000 | H-B 24 TBF M25 | 25 | | | 5 |
| 19117000 | H-B 24 TBF M32 | 32 | | | 5 |

Footnote:

Photographs are not to scale and do not represent detailed images of the respective products.