


These connectors are attractive because of their compact housing.

Product Description

Small and space-saving for narrow available space

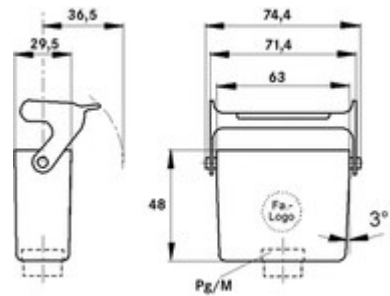

Application range

- Machine and equipment manufacturing
- Control engineering
- Electronic laboratory

Benefits

- Small and space-saving for narrow available space

Product features

- Cable coupler hood, low version
- Single lever
- Straight cable entry
- Versions with / without neck



Technical Data

Material

Housing: aluminium alloy, grey Lever: zinc-plated steel Sealing: NBR

Protection rating

IP 65 (latched)

Temperature range

-40 °C to +100 °C, short-term up to +125 °C

Article List

Part number	Article	M	PG	Neck	Pieces / PU
H-A housing: cable coupler hood (straight cable entry, single lever)					
10439000	H-A 10 TBF-LB 13,5		13.5	yes	5
70450000	H-A 10 TBF-LB 16		16	yes	5
19439000	H-A 10 TBF-LB M20	20			5
79450000	H-A 10 TBF-LB M25	25			5

Footnote:

Photographs are not to scale and do not represent detailed images of the respective products.