


BN:739898

MN:HN9801

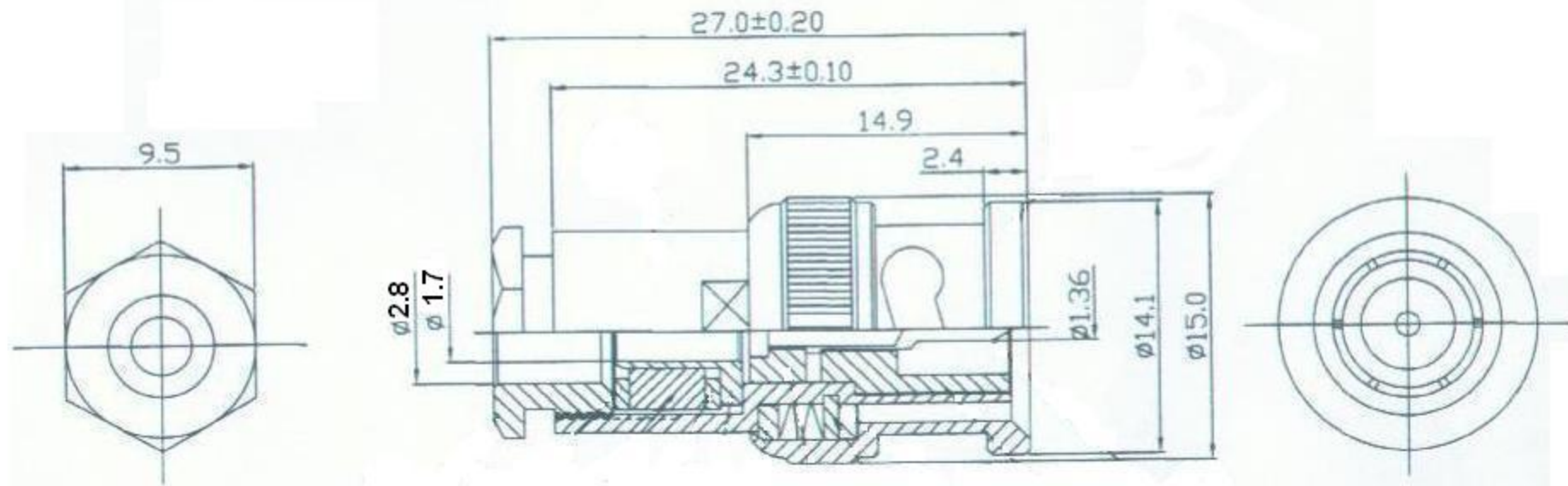

SPEC.

Temperature Range : $-55 \sim +155^{\circ}\text{C}$ (PE cable $-40 \sim +85^{\circ}\text{C}$)

Impedance : 50 Ω

Frequency Range : DC \sim 4GHz

Working Voltage : 500V r.m.s at sea level

Insulation resistance : $\geq 5000\text{M}\Omega$

Insertion Loss : $\leq 0.20\text{dB}/3\text{GHz}$

Tolerance : 0.5mm

Drawing : Tammy

Date : 2009-03-05

Approval : Kylie