


Housing design H-B. The industry standard.

## Product Description

The smallest housing with single and double lever. The right housing is available for every application

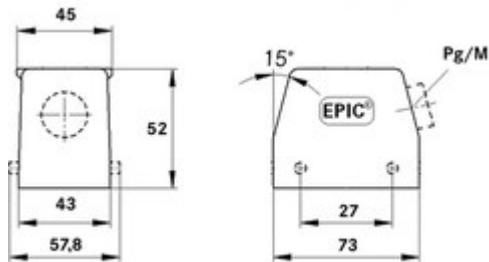

## Application range

- Plant engineering
- Light & sound technology
- Plastics industry

## Benefits

- The smallest housing with single and double lever. The right housing is available for every application

## Product features

- Hood, low version
- Bolts for double lever
- Side cable entry
- Versions with neck



**Technical Data**

**Material**

Housing: powder-coated aluminium alloy, grey

Lever: zinc-plated steel Sealing: NBR

**Protection rating**

IP 65 (latched)

**Temperature range**

-40 °C to +100 °C, short-term up to +125 °C

**Article List**

Part number	Article	M	PG	Neck	Pieces / PU
H-B housing: hood (side cable entry, bolts for double lever)					
10042000	H-B 10 TS 16		16	yes	10
10042100	H-B 10 TS 21		21	yes	10
19042000	H-B 10 TS M20	20		yes	10
19042100	H-B 10 TS M25	25		yes	10

**Footnote:**

Photographs are not to scale and do not represent detailed images of the respective products.