
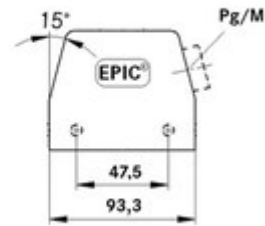


Housing design H-B. The industry standard.

## Product Description

The housing standard. Wide choice for all applications

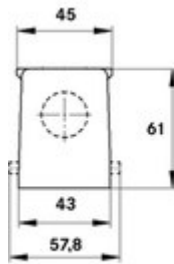

## Application range

- Plant engineering
- Light & sound technology
- Plastics industry

## Benefits

- The housing standard. Wide choice for all applications

## Product features

- Hood, low version
- Bolts for double lever
- Side cable entry
- Versions with neck



**Technical Data**

**Material**

Housing: powder-coated aluminium alloy, grey

Lever: zinc-plated steel Sealing: NBR

**Protection rating**

IP 65 (latched)

**Temperature range**

-40 °C to +100 °C, short-term up to +125 °C

**Article List**

Part number	Article	M	PG	Neck	Pieces / PU
H-B housing: hood (side cable entry, bolts for double lever)					
10082000	H-B 16 TS 21		21	yes	5
10092000	H-B 16 TS 29		29	yes	5
19082000	H-B 16 TS M25	25		yes	5
19092000	H-B 16 TS M32	32		yes	5

**Footnote:**

Photographs are not to scale and do not represent detailed images of the respective products.