


**PIN HEADER 2,00 mm**

**ID: 150**


STL 12-XXG / STL 22-XXG

Series 500

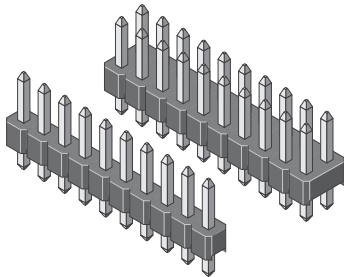

**TECHNICAL DATA**

|                               |                                       |
|-------------------------------|---------------------------------------|
| Pitch                         | 2,00 mm                               |
| Insulating Material           | high temp. thermoplast UL94V-0        |
| Contact Material              | copper alloy                          |
| Rated Current                 | 1,5 Amp.                              |
| Rated Voltage                 | 150 V <sub>RMS</sub> /V <sub>DC</sub> |
| Withstanding Voltage          | 500 V <sub>AC</sub> for one minute    |
| Operating Temperature         | -40°C to +105°C                       |
| Maximum Soldering Temperature | 260°C for 10 seconds                  |

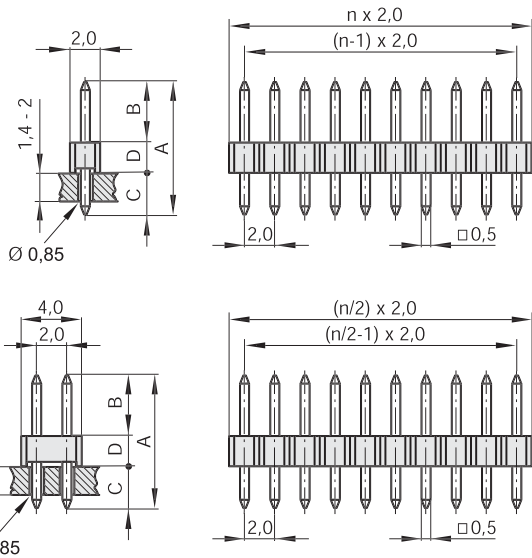

for D = 1,5mm

| Code   | A     | B     | C     |
|--------|-------|-------|-------|
| 0785   | 7,85  | 4,00  | 2,35  |
| 0835   | 8,35  | 4,00  | 2,85  |
| 0870   | 8,70  | 4,40  | 2,80  |
| 1015   | 10,15 | 5,65  | 3,00  |
| 1020   | 10,20 | 5,85  | 2,85  |
| 1155   | 11,55 | 7,00  | 3,05  |
| 1340   | 13,40 | 9,15  | 2,75  |
| 1555   | 15,55 | 11,55 | 2,50  |
| custom | _____ | _____ | _____ |

for D = 2,0mm

| Code   | A     | B     | C     |
|--------|-------|-------|-------|
| 0785   | 7,85  | 3,50  | 2,35  |
| 0835   | 8,35  | 3,50  | 2,85  |
| 0870   | 8,70  | 3,90  | 2,80  |
| 1015   | 10,15 | 5,15  | 3,00  |
| 1020   | 10,20 | 5,35  | 2,85  |
| 1155   | 11,55 | 6,50  | 3,05  |
| 1340   | 13,40 | 8,65  | 2,75  |
| 1555   | 15,55 | 11,05 | 2,50  |
| custom | _____ | _____ | _____ |

All dimensions in mm.  
Other dimensions upon request.

**STL XX - XXXX - X,X - G XX - XX U**

