

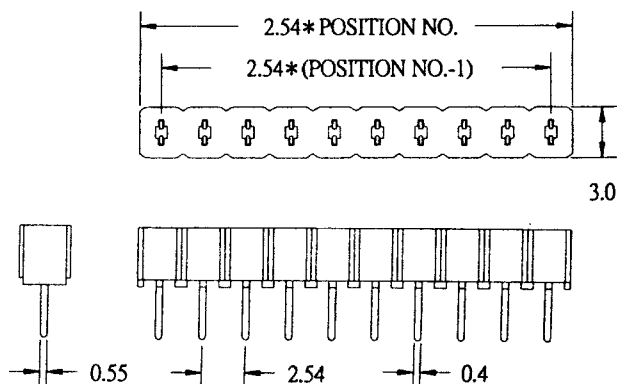
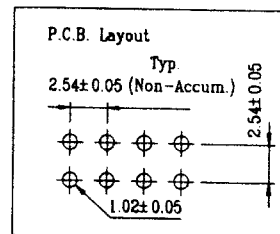
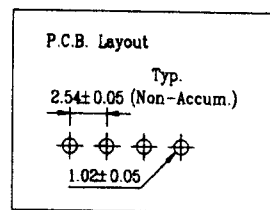


2.54MM(0.100") FEMALE HEADER STRAIGHT TYPE PROFILE=3.50MM

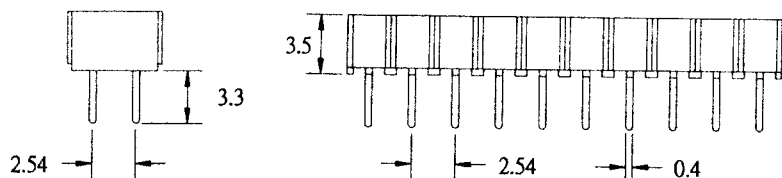

SPECIFICATIONS

- Current rating: 3 Amps
- Insulator resistance: 5000 megohms min.
- Contact resistance: 20 m ohm Max.
- Dielectric withstanding: AC 500 V
- Operating temperature: -40° - +105°C
- Contact material: phosphor bronze
- Insulator material: polyester, UL 94V-0
- ©Standard: P.B.T

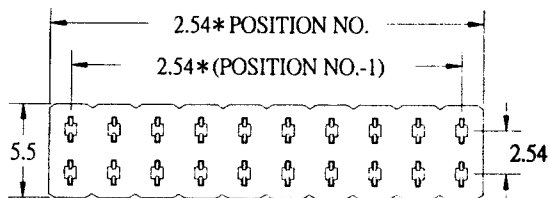

PART NO.

2 5 4 $\frac{x x}{1}$ - $\frac{x x x}{2}$ $\frac{G B}{3}$

1. NO. OF ROWS:
"AL" SINGLE ROW
"AM" DOUBLE ROW
2. NO. OF CONTACTS:
002 till 050 for SINGLE ROW
004 till 100 for DOUBLE ROW
3. CONTACT FINISH:
"G" FULL GOLD PLATED