



FEMALE HEADER 2,00 mm
ID: 317 BL 12-43A

Series 501

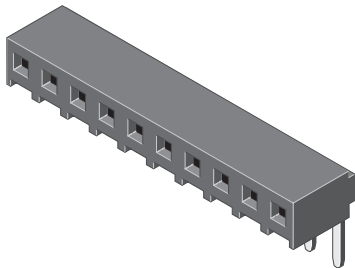


TECHNICAL DATA

Pitch	2,00 mm
Insulating Material	high temp. thermoplast UL94V-0
Contact Material	phosphor bronze
Rated Current	1,5 Amp.
Rated Voltage	100 V _{RMS} /150 V _{DC}
Withstanding Voltage	500 V _{AC} for one minute
Operating Temperature	-40°C to +105°C
Maximum Soldering Temperature	260°C for 10 seconds

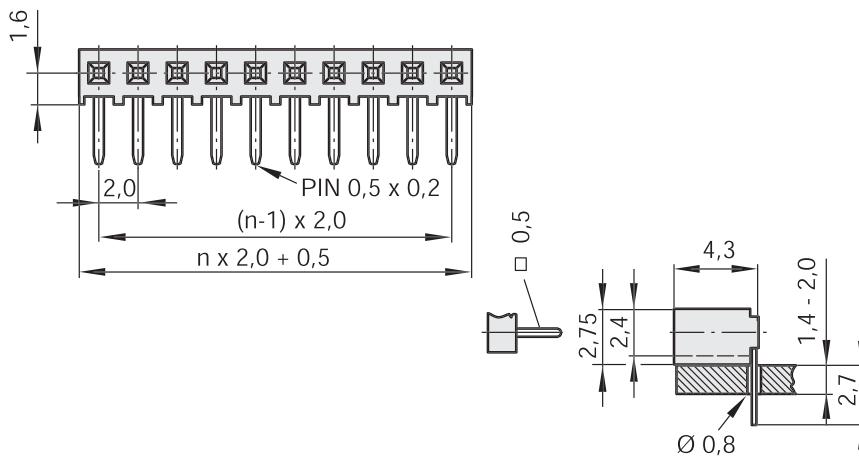

All dimensions in mm.
 Other dimensions upon request.

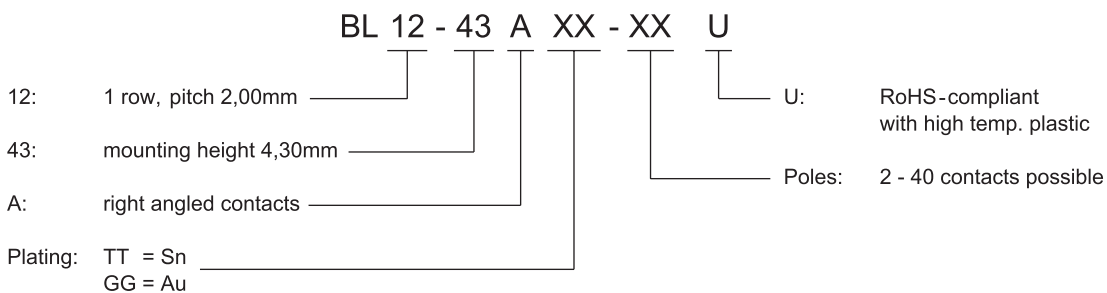

8 | 2,00 mm