


SPECIFICATIONS

- Current Rating:** 3.0 Amp
- Contact Resistance:** 4mΩ Max.
- Insulation Resistance:** 1000MΩ Min
- Operating Voltage:** 60V AC/DC
- Operating Temperature:**
 - Gold Plated: -55°C to + 105°C
 - Tin Plated: -40°C to + 105°C
- Soldering Temperature:** 260°C for 10 seconds max.

MATERIALS

- Insulation Material:** PPS, UL 94V-0
- Contact Material:** Brass
- All materials must be RoHS compliant.**

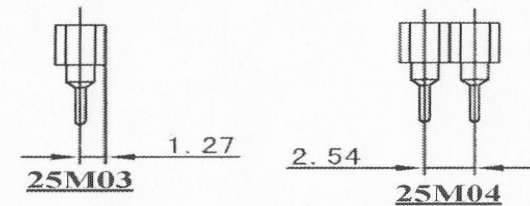

Datenblatt passend für den Artikel
10120832 / 10120834 / 10120836