

SPECIFICATIONS

Current Rating: 3.0 Amp

Contact Resistance: 4mΩ Max.

Insulation Resistance: 1000MΩ Min

Operating Voltage: 60V AC/DC

Operating Temperature:

Gold Plated: -55°C to + 105°C

Tin Plated: -40°C to + 105°C

Soldering Temperature: 260°C






for 10 seconds max.

MATERIALS

Insulation Material: PPS, UL 94V-0

Contact Material: Brass

All materials must be RoHS compliant.

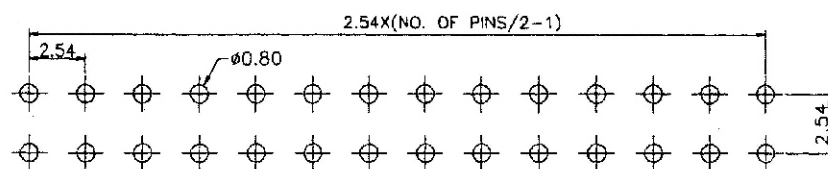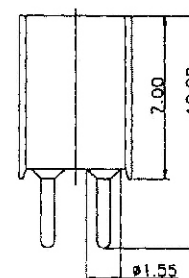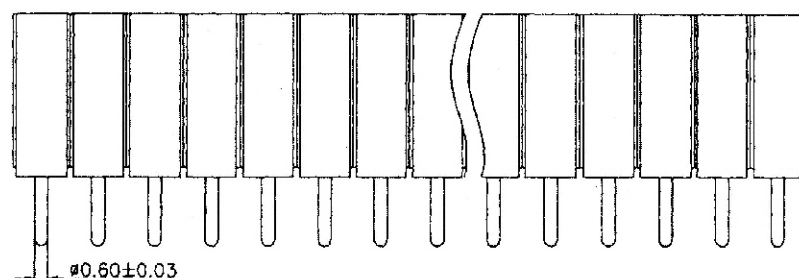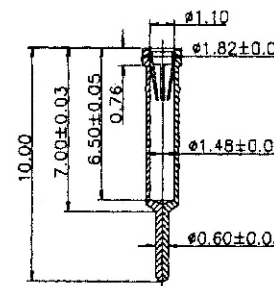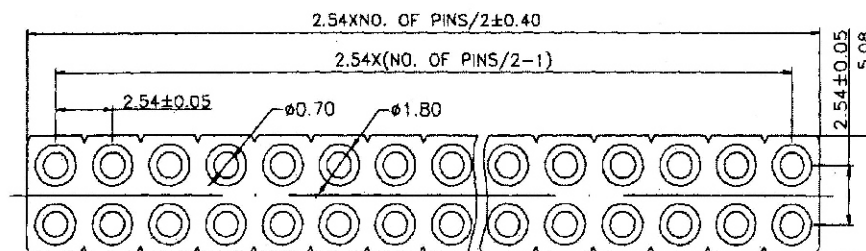

Recommended P.C.Board Layout

Datenblatt passend zu folgenden Artikelnummern
10120844 / 10120846 / 10120848 / 10120850 / 10120852 / 10120854