
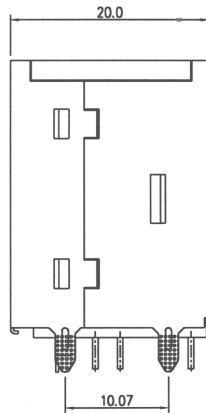


### MiniDIN-Steckverbinder, geschirmt, dual Port, 6 polig, grün-violett MiniDIN-connector, shielded, dual port, 6 poles, green-purple

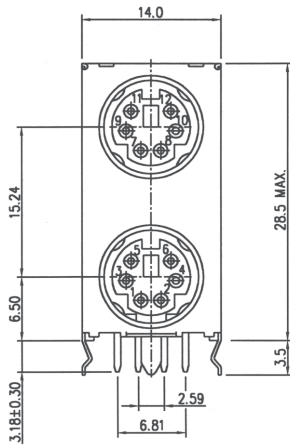

**Isolierkörper**  
PBT, 30% Glasfaser verstärkt

**Strombelastbarkeit**  
2A DC

**Nennspannung**  
12V DC

**Kontaktwiderstand**  
30mΩ max

**Durchschlagsspannung**  
500V AC / 1 Minute

**Isolationswiderstand**  
500MΩ min. bei 500V DC

**Insulator**  
PBT, 30% glasfiber reinforced


**Current rating**  
2A DC

**Current voltage**  
12V DC

**Contact resistance**  
30mΩ max.

**Dielectric strength**  
500V DC / 1 minute

**Insulations resistance**  
500MΩ min. at 500V DC

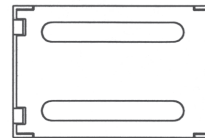

Bestellcode : **A - DIO - DP / 06 - GV**  
Ordercode :



**Isolierkörper**  
PBT, UL94V-0

**Kontakte**  
Messing, Verzinkt

**Strombelastbarkeit**  
2A DC

**Nennspannung**  
12V DC

**Kontaktwiderstand**  
100mΩ max

**Betriebstemperatur**  
-25°C - +85°C

**Insulator**  
PBT, UL94V-0




**Contacts**  
Brass, tin plated

**Current rating**  
2A DC

**Current voltage**  
12V DC

**Contact resistance**  
100mΩ max.

**Operating temperature**  
-25°C - +85°C

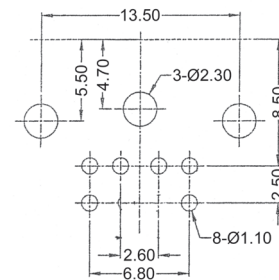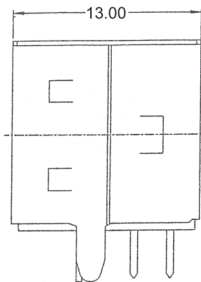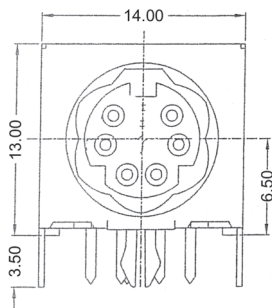

Ansicht von unten  
Bottom view

Bestellcode : **A - DIO - FS - 06 - x**  
Ordercode :

1.

**Farbe**  
Green -Grün  
Purple -Violett

1.

**Color**  
Green -Green  
Purple -Purple