

Mounting base housing - BC 35,6 UT HBUS BK - 2896254

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Lower part for installation housing BC 35,6...

Key commercial data

package_quantity	10
GTIN	4046356096706

Technical data

General

Housing type	Installation component housing
Housing material	polycarbonate
Color	black

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
--	-------------------

Dimensions

Length	89.7 mm
Constructional height	49 mm
Width	35.6 mm

Technical data

Inflammability class according to UL 94	V0
Power dissipation at 20°C in the horizontal mounting position	4.78 W

classifications

eCl@ss

eCl@ss 4.0	27180401
eCl@ss 4.1	27180401
eCl@ss 5.0	27180506
eCl@ss 5.1	27180506
eCl@ss 6.0	27180802
eCl@ss 7.0	27182702
eCl@ss 8.0	27182702

Mounting base housing - BC 35,6 UT HBUS BK - 2896254

classifications

ETIM

ETIM 2.0	EC001031
ETIM 3.0	EC001031
ETIM 4.0	EC001031
ETIM 5.0	EC001031




UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

approvals

UL Recognized / GOST / GOST /

   
Approval details



Drawings

Mounting base housing - BC 35,6 UT HBUS BK - 2896254


Dimensioned drawing

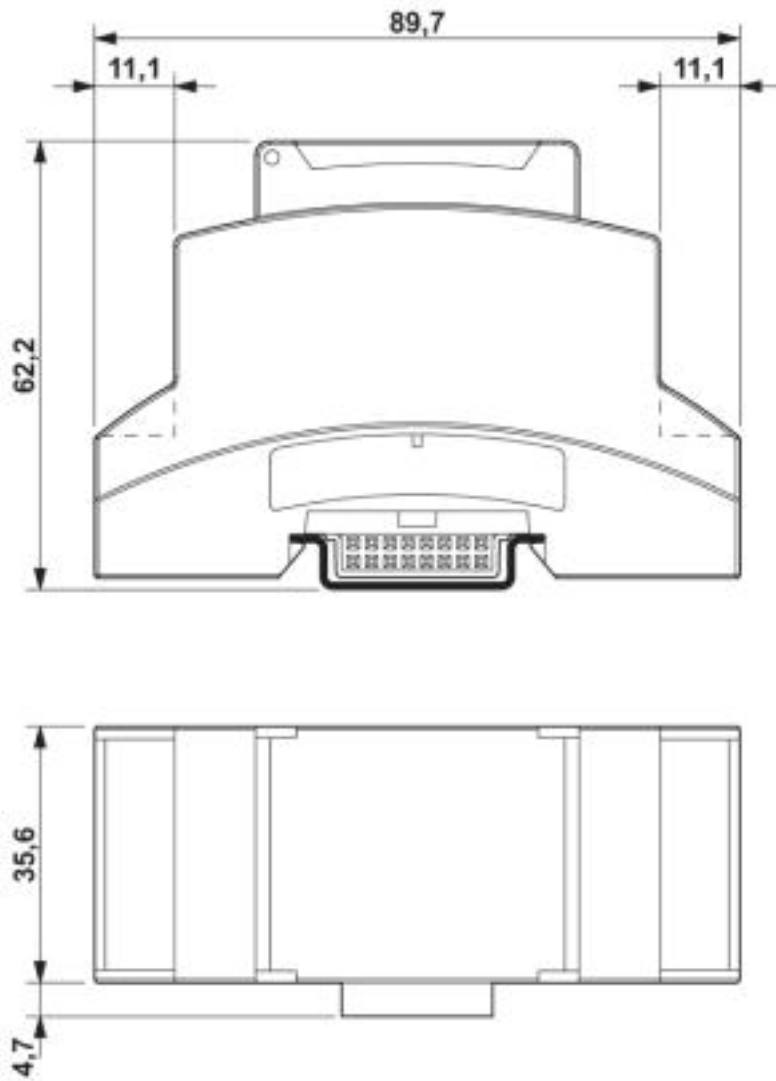

The dimensional drawing shows the item along with the lower part of the housing (terminal installation depth 11.1 mm) and the housing cover

Mounting base housing - BC 35,6 UT HBUS BK - 2896254

Dimensioned drawing

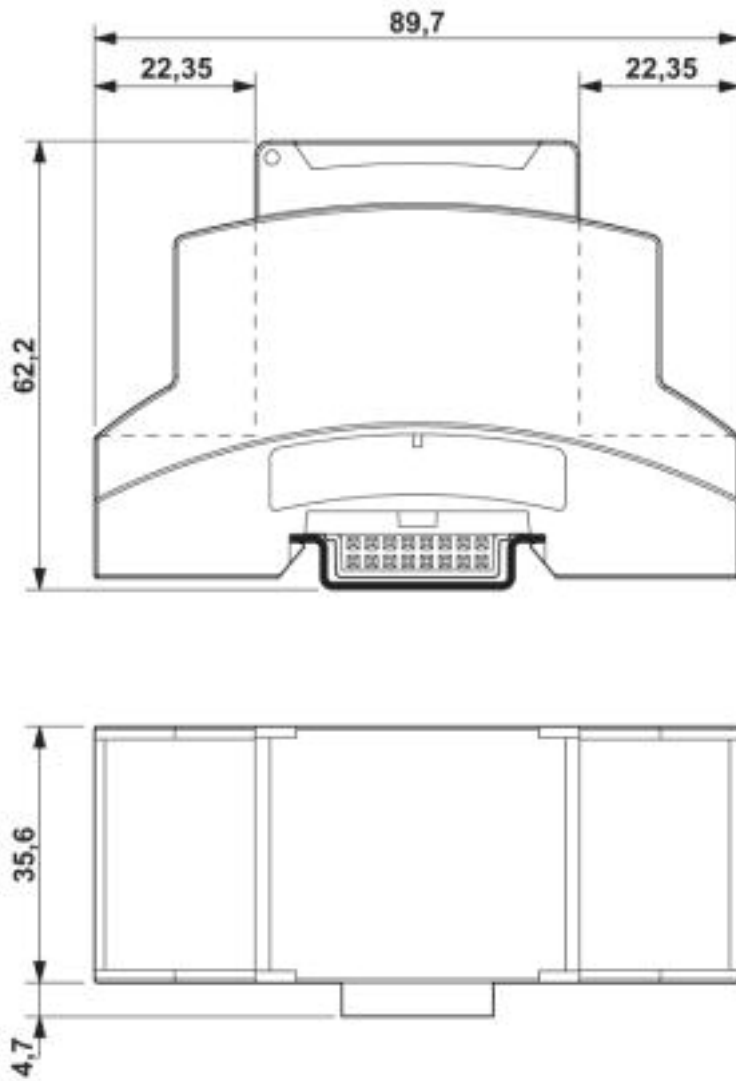

The dimensional drawing shows the item along with the lower part of the housing (terminal installation depth 22.35 mm) and the housing cover

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>