


SUB D Steckverbindungen



Sub D Steckverbindungen Lätanschluss

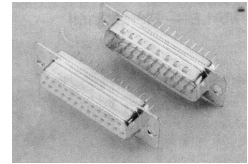

5201/5202- -

	Art.Nr. Stiftleiste	Art.Nr. Buchsenleiste
9-pol	742066	742082
15-pol	741663	741680
25-pol	741671	741698
37-pol	741400	741426
50-pol	741418	741485

Polzahl	A	B	C	D	E	F
9	16,92	24,99	30,81	19,28	16,33	
25	25,25	33,32	39,14	27,51	24,66	
25	38,96	47,04	53,04	41,30	38,38	
37	55,42	63,50	69,32	57,71	54,84	
50	52,86	61,11	66,90	55,30	52,34	

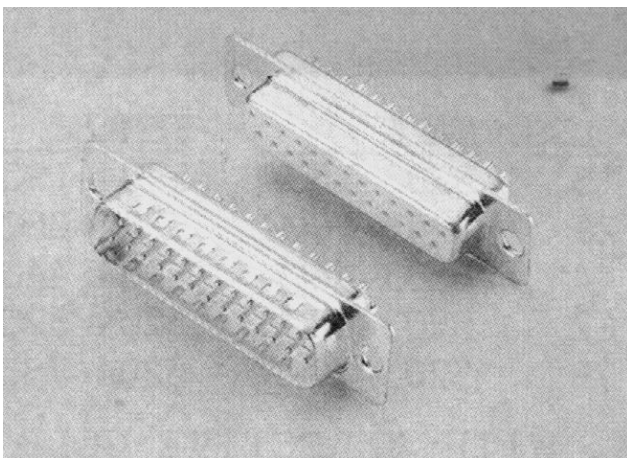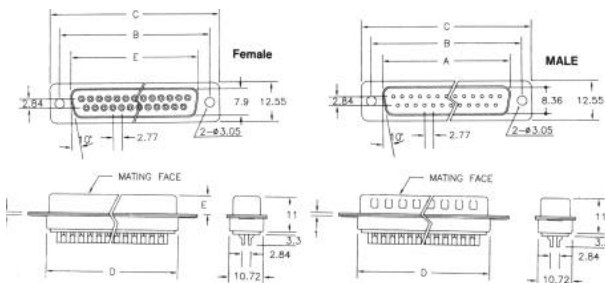

lagermässige Ausführungen

Techn. Daten

Contact resistance

30mOhm max. at DC 100mA

Insulator resistance

1000MOhm min. at DC 500V

Current rating

5 A

Dielectric withstanding

Voltage

AC 1000V for 1 min.

Operating temperature

-55°C ~ +105°C

Contact

brass or phosphor bronze

Housing

PBT & 30% glass fiber
(UL94V)

Ausführung

tin-plated-shell
white plastic insert

Die Steckverbinder sind nicht für Starkstromnetze im Sinne VDE geeignet!