



SUB D Adapter

Sub D MINI GENDER CHANGER

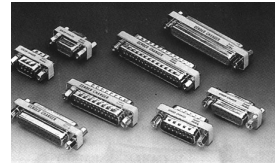

AD- -

	Art.Nr. Stecker/Stecker	Art.Nr. Buchse/Buchse
9-pol	741620	741639
15-pol	738284	738272
25-pol	741647	741655
37-pol	742791	742783

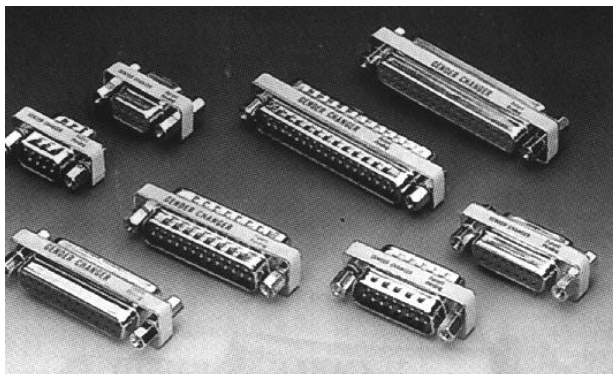

lagermassige Ausführungen

Techn. Daten

Contact resistance	30mOhm max. at DC 100mA
Insulator resistance	1000MOhm min. at DC 500V
Current rating	5 A
Dielectric withstanding Voltage	AC 1000V for 1 min.
Operating temperature	-55°C ~ +105°C
Contact	brass or phosphor bronze
Housing	PBT & 30% glass fiber (UL94V)
Ausführung	tin-plated-shell black plastic insert

Die Steckverbinder sind nicht für Starkstromnetze im Sinne VDE geeignet!