

D-SUB contact insert - VS-15-BU-DSUB/16-MPT-0,5 - 1688094

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



D-SUB contact insert, shell size 2, with 15 signal contacts, female contact type, screw connection, straight, for panel mounting frame and sleeve housing with IP67 protection

Key commercial data

| | |
|-------------------------|---------------|
| package_quantity | 10 |
| GTIN | 4017918179571 |

Technical data

Mechanical characteristics

| | |
|--|--|
| Number of positions | 15 |
| Connection profile | D-SUB 15 |
| Insertion/withdrawal cycles | ≤ 200 |
| Connection method | Screw connection |
| Conductor cross section | 0.14 mm ² ... 0.5 mm ² |
| Connection cross section AWG | 26 ... 20 |
| Insertion force per signal contact | ≤ 3.30 N |
| Extraction force per signal contact | ≤ 2.2 N |

Ambient conditions

| | |
|--|------------------|
| Ambient temperature (operation) | -20 °C ... 80 °C |
| Degree of protection | IP20 |

Material data

| | |
|--|------------------|
| Inflammability class according to UL 94 | V0 |
| Contact carrier material | PBTP |
| Contact material | Copper alloy |
| Contact surface material | Gold over nickel |

Electrical characteristics

| | |
|--|-----------|
| Rated voltage (III/3) | 60 V |
| Rated current | 5 A |
| Contact resistance per contact pair | ≤ 2.5 mΩ |
| Insulation resistance | ≥ 5000 MΩ |

D-SUB contact insert - VS-15-BU-DSUB/16-MPT-0,5 - 1688094

classifications

eCl@ss

| | |
|------------|----------|
| eCl@ss 4.0 | 27140816 |
| eCl@ss 4.1 | 27260701 |
| eCl@ss 5.0 | 27260701 |
| eCl@ss 5.1 | 27260701 |
| eCl@ss 6.0 | 27260705 |
| eCl@ss 7.0 | 27440309 |
| eCl@ss 8.0 | 27440309 |

ETIM

| | |
|----------|----------|
| ETIM 2.0 | EC000438 |
| ETIM 3.0 | EC000438 |
| ETIM 4.0 | EC000438 |
| ETIM 5.0 | EC000438 |

 
 
UNSPSC

| | |
|---------------|----------|
| UNSPSC 6.01 | 30211923 |
| UNSPSC 7.0901 | 39121522 |
| UNSPSC 11 | 39121522 |
| UNSPSC 12.01 | 39121522 |
| UNSPSC 13.2 | 39121522 |

approvals

GOST / GOST /



Approval details



Drawings

D-SUB contact insert - VS-15-BU-DSUB/16-MPT-0,5 - 1688094

Dimensioned drawing

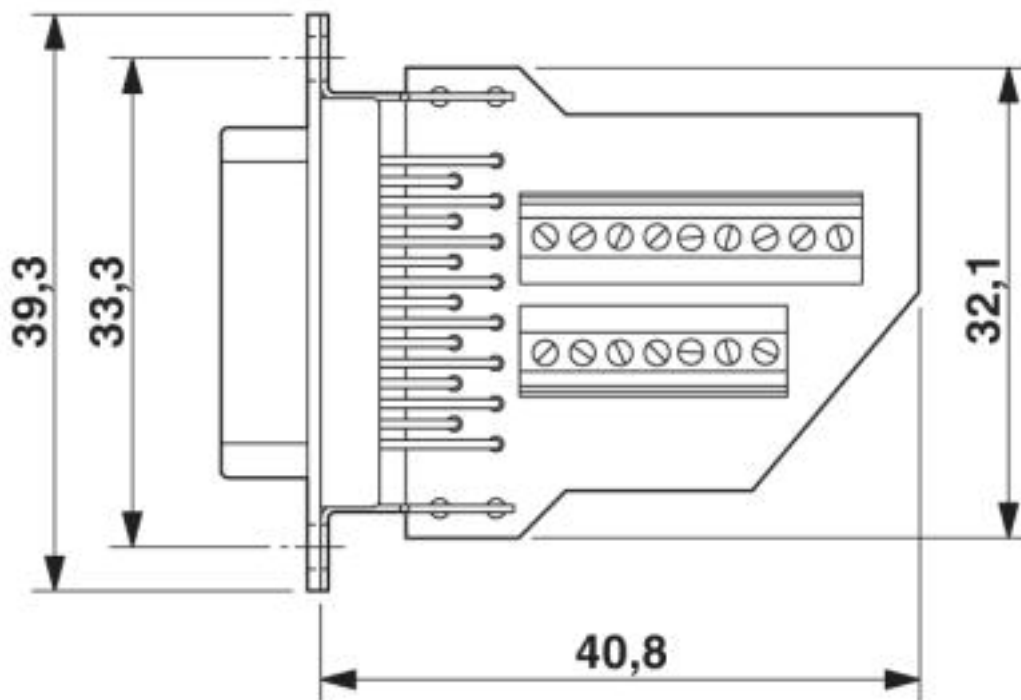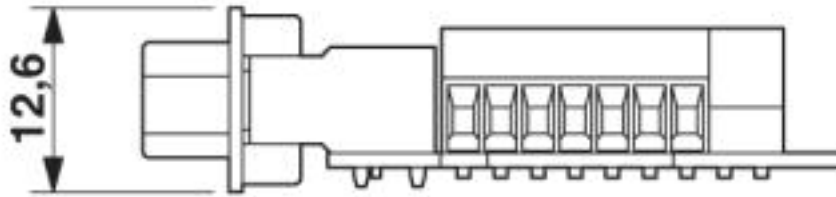

D-SUB contact insert

Schematic diagram