

Date: 01.12.2010

RRJVA_RJ45_STB


Technical Data

Type reference: RRJVA_RJ45_STB
Description: flush-mounting jack RJ45
with screen cat6

Jack front side: RJ45 8/8
Jack back side: RJ45 8/8

Protection degree:
RRJ_RJ45_STB
in combination with AK22RR IP6X (X= depending on the mounting position)
IP67

Mounting diameter 22.3mm
Storage temperature: -25°C ... +80°C
Ambient temperature: -20°C ... +60°C

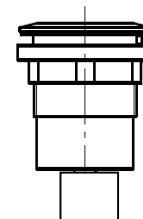

- Änderungen vorbehalten -