


Date: 01.12.2010

RRJVA_USB_AA

Technical Data

Type reference: RRJVA_USB_AA
Specification: USB 2.0

USB jack, front side: Type A
USB jack, back side: Type A

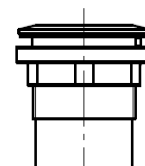

Protection degree: IP65

Mounting diameter: 22.3mm
Storage temperature: -25°C ... +80°C
Operating temperature max.: -20°C ... +60°C

- Subject to alterations -