


Date: 01.12.2010

## RRJVA\_USB\_AB

### Technical Data

Type reference: RRJVA\_USB\_AB  
Specification: USB 2.0

USB jack, front side: Type A  
USB jack, back side: Type B

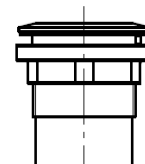

Protection degree: IP65

Mounting diameter: 22.3mm  
Storage temperature: -25°C ... +80°C  
Operating temperature max.: -20°C ... +60°C

- Subject to alterations -