

Date: 01.12.2010

RRJVA_USB_BA


Technical Data

Type reference: RRJVA_USB_BA
Specification: USB 2.0

USB jack, front side: Type B
USB jack, back side: Type A

Protection degree: IP65

Mounting diameter: 22.3mm
Storage temperature: -25°C ... +80°C
Operating temperature max.: -20°C ... +60°C

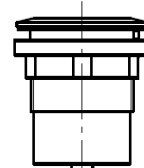

- Subject to alterations -