

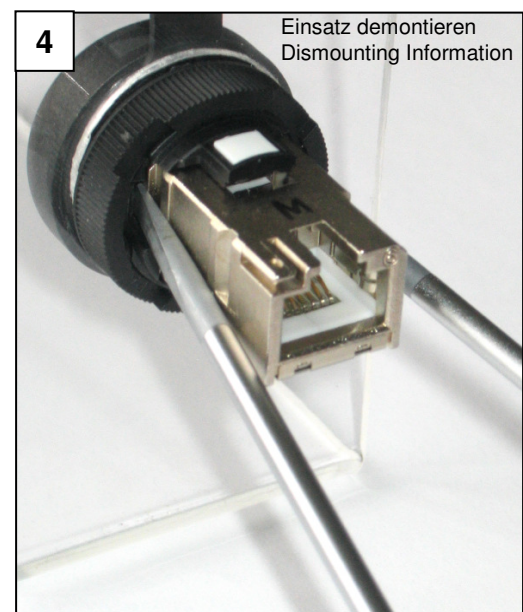
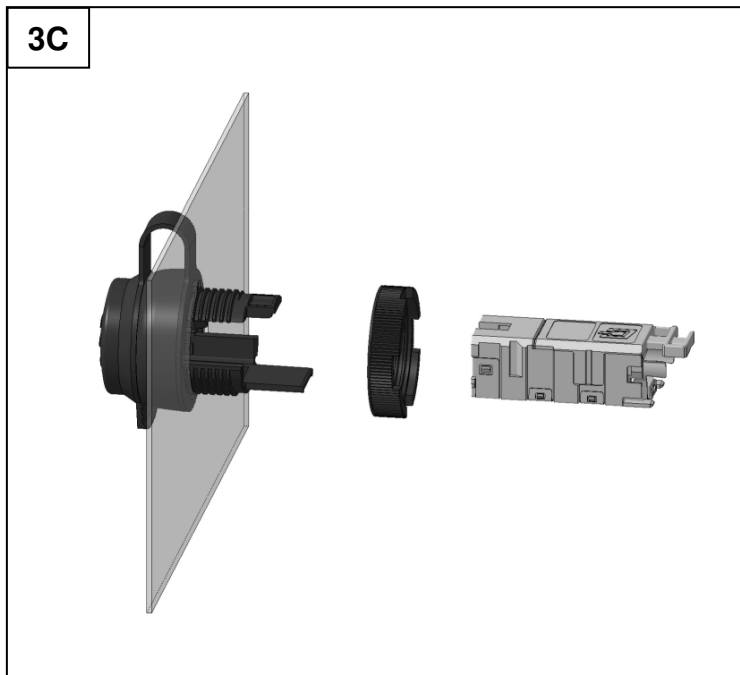
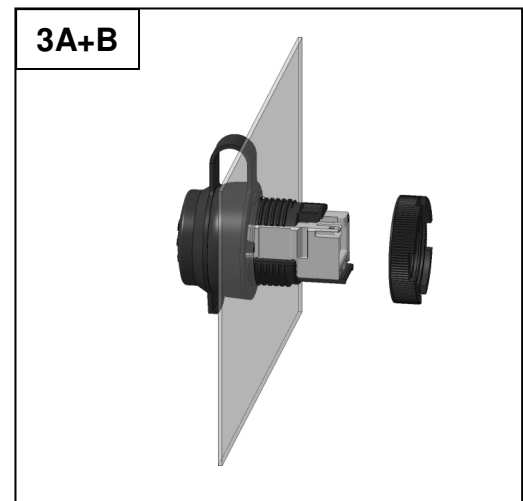


1018790000 IE-FCM-RJ45-C / 1018810000 IE-FCM-RJ45-FJ-A / 1018820000 IE-FCM-RJ45-FJ-B /
1018830000 IE-FCM-RJ45-FJ-P / 1018840000 IE-FCM-USB-A / 1222550000 IE-FCM-USB-AB

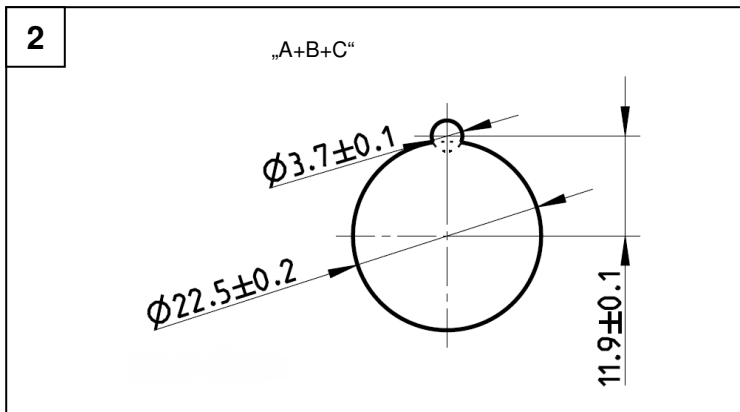

Montagehinweis / Mounting information / Référence de montage / Indicaciones de montaje / Informazioni per il montaggio

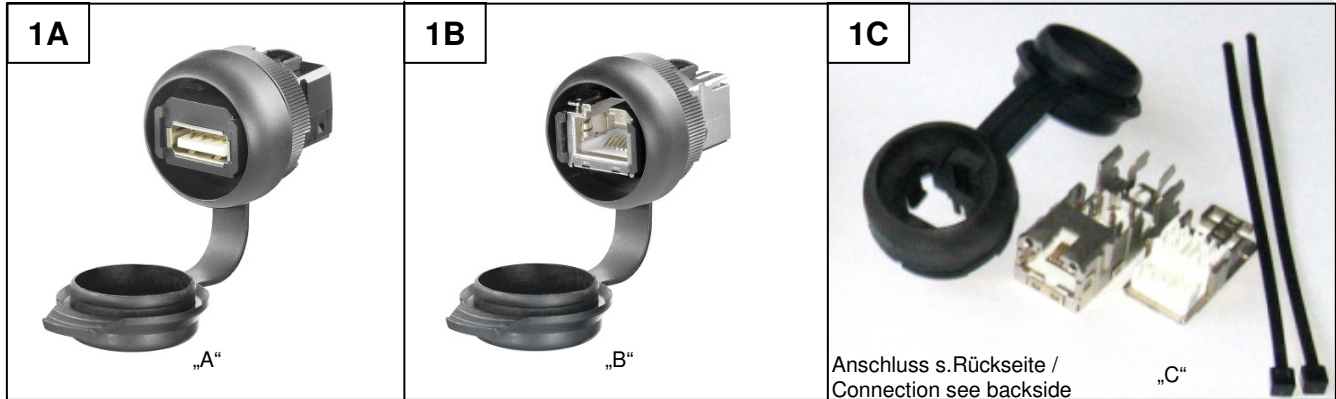

WM-4342590000-02

**Weidmüller Interface
GmbH & Co. KG**
Postfach 3030
32720 Detmold / Germany

Tel.: +49 (0)5231/14-0
Fax: +49 (0)5231/14-2083
E-mail: info@weidmueller.com
<http://www.weidmueller.com>

Montageanleitung siehe
Mounting instructions see
Instructions de montage
Instrucciones de montaje
Istruzioni per il montaggio : www.weidmueller.com

„C“

Anschluss / Connection					Anwendung / Application						
RJ45 PIN Nr./No.	Farbcode / Colour code T568 A B		DIN 47100	Industrial Eth.	10BT/ 100BT	Gigabit Ethernet	Token Ring	ISDN/So	TP-PMD/ ATM	ISDN/ So	Upo/ TEL
1	WH-GN	WH-OG	WH	YE	*	*			*		
2	GN	OG	BN	OG	*	*			*		
3	WH-OG	WH-GN	GN	WH	*	*	*			2a	
4	BU	BU	YE	-		*	*			1a	*
5	WH-BU	WH-BU	GY	-		*	*			1b	*
6	OG	GN	PK	BU	*	*	*			2b	
7	WH-BN	WH-BN	BU	-		*			*		
8	BN	BN	RD	-		*			*		

