

Installation terminal block - PTI 6-PE - 3213966

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)



Installation terminal block, Push-in connection, Cross section: 0.5 mm² - 10 mm², AWG: 20 - 8, Width: 8.2 mm, Color: green-yellow, Mounting type: NS 35/7,5, NS 35/15

Product Features

- Same shape and pitch as the feed-through terminal blocks
- Contact is made free from mechanical and electrical errors by simply snapping onto the DIN rail
- All the requirements of standard IEC 60947-7-2 are met

Key commercial data

package_quantity	50
GTIN	4046356609364

Technical data

General

Number of levels	1
Number of connections	2
Color	green-yellow
Insulating material	PA
Inflammability class according to UL 94	V0

General

Rated surge voltage	8 kV
Pollution degree	3
Surge voltage category	III
Insulating material group	I
Connection in acc. with standard	IEC 60947-7-2
Open side panel	ja
Shock protection test specification	DIN EN 50274 (VDE 0660-514):2002-11
Back of the hand protection	guaranteed
Finger protection	guaranteed
Test specification, oscillation, broadband noise	DIN EN 50155 (VDE 0115-200):2008-03
Test spectrum	Service life test category 2, bogie mounted
Test frequency	f ₁ = 5 Hz to f ₂ = 250 Hz
ASD level	6.12 (m/s ²) ² /Hz
Acceleration	3.12 g

Installation terminal block - PTI 6-PE - 3213966

Technical data

General

Test duration per axis	5 h
Test directions	X-, Y- and Z-axis
Oscillation, broadband noise test result	Test passed
Test specification, shock test	DIN EN 50155 (VDE 0115-200):2008-03
Shock form	Half-sine
Acceleration	30 g
Shock duration	18 ms
Number of shocks per direction	3
Test directions	X-, Y- and Z-axis (pos. and neg.)
Shock test result	Test passed
Temperature index, insulating material (DIN EN 60216-1 (VDE 0304-21))	130 °C
Static insulating material application in cold	-60 °C

Dimensions

Width	8.2 mm
Length	66 mm
Height	48.50 mm
Height NS 35/7,5	50 mm
Height NS 35/15	57.5 mm

Connection data

Conductor cross section solid min.	0.5 mm ²
Conductor cross section solid max.	10 mm ²
Conductor cross section AWG/kcmil min.	20
Conductor cross section AWG/kcmil max	8
Conductor cross section stranded min.	0.5 mm ²
Conductor cross section stranded max.	6 mm ²
Min. AWG conductor cross section, stranded	20
Max. AWG conductor cross section, stranded	10
Conductor cross section stranded, with ferrule without plastic sleeve min.	0.5 mm ²
Conductor cross section stranded, with ferrule without plastic sleeve max.	6 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve min.	0.5 mm ²
Conductor cross section stranded, with ferrule with plastic sleeve max.	6 mm ²
2 conductors with same cross section, stranded, TWIN ferrules with plastic sleeve, min.	0.5 mm ²
2 conductors with same cross section, stranded, TWIN ferrules with plastic sleeve, max.	1.5 mm ²
Connection method	Push-in connection
Stripping length	12 mm
Internal cylindrical gage	A5

Installation terminal block - PTI 6-PE - 3213966

Technical data

classifications

eCl@ss

eCl@ss 4.0	27141111
eCl@ss 4.1	27141111
eCl@ss 5.0	27141141
eCl@ss 5.1	27141141
eCl@ss 6.0	27141141
eCl@ss 7.0	27141141
eCl@ss 8.0	27141141

ETIM

ETIM 4.0	EC000901
ETIM 5.0	EC000901


UNSPSC

UNSPSC 6.01	30211811
UNSPSC 7.0901	39121410
UNSPSC 11	39121410
UNSPSC 12.01	39121410
UNSPSC 13.2	39121410

approvals

GOST / GL /

 Approval details



accessories

End cover

D-DTI 6 - 3034947



Installation terminal block - PTI 6-PE - 3213966

accessories

DP PS-8 - 3036741



Partition plate

ATP-ST 6 - 3024481



ATP-PTI/3 - 3213990



Screwdriver tools

SZF 2-0,8X4,0 - 1204520



Support

AB-PTI 6 - 3214008



Installation terminal block - PTI 6-PE - 3213966

accessories

Documentation

PT-IL - 3208090



Bridge

FBS 2-8 - 3030284



FBS 3-8 - 3030297



FBS 4-8 - 3030307



FBS 5-8 - 3030310



Installation terminal block - PTI 6-PE - 3213966

accessories

FBS 10-8 - 3030323



FBS 6-8 - 3032470



FBSRH 2-8 - 3033802



FBSRH 3-8 - 3033803



FBSRH 4-8 - 3033804



Mounting rail

Installation terminal block - PTI 6-PE - 3213966

accessories

NS 35/ 7,5 PERF 2000MM - 0801733



NS 35/ 7,5 UNPERF 2000MM - 0801681



NS 35/ 7,5 WH PERF 2000MM - 1204119



NS 35/ 7,5 WH UNPERF 2000MM - 1204122



NS 35/ 7,5 AL UNPERF 2000MM - 0801704



NS 35/ 7,5 ZN PERF 2000MM - 1206421



Installation terminal block - PTI 6-PE - 3213966

accessories

NS 35/ 7,5 ZN UNPERF 2000MM - 1206434



NS 35/ 7,5 CU UNPERF 2000MM - 0801762



NS 35/ 7,5 CAP - 1206560



NS 35/15 PERF 2000MM - 1201730



NS 35/15 UNPERF 2000MM - 1201714



Installation terminal block - PTI 6-PE - 3213966

accessories

NS 35/15 WH PERF 2000MM - 0806602



NS 35/15 WH UNPERF 2000MM - 1204135



NS 35/15 AL UNPERF 2000MM - 1201756



NS 35/15 ZN PERF 2000MM - 1206599



NS 35/15 ZN UNPERF 2000MM - 1206586



NS 35/15 CU UNPERF 2000MM - 1201895



Installation terminal block - PTI 6-PE - 3213966

accessories

NS 35/15 CAP - 1206573



NS 35/15-2,3 UNPERF 2000MM - 1201798



Terminal marking

ZBF 5:UNBEDRUCKT - 0808642



UC-TMF 5 - 0818153



UCT-TMF 5 - 0828744



Installation terminal block - PTI 6-PE - 3213966

accessories

ZB 8:UNBEDRUCKT - 1052002



UC-TM 8 - 0818072



UCT-TM 8 - 0828740



ZBF 8:UNBEDRUCKT - 0808781



UC-TMF 8 - 0818137



UCT-TMF 8 - 0828748



Installation terminal block - PTI 6-PE - 3213966

accessories

TMT (EX9,5)R - 0828295



Labeled terminal marker

ZBF 5 CUS - 0825025



UC-TMF 5 CUS - 0824638



UCT-TMF 5 CUS - 0829658



ZB 8 CUS - 0825011



Installation terminal block - PTI 6-PE - 3213966

accessories

UC-TM 8 CUS - 0824597



UCT-TM 8 CUS - 0829616



ZBF 8 CUS - 0825030



UC-TMF 8 CUS - 0824654



UCT-TMF 8 CUS - 0829672



Test plug terminal block

Installation terminal block - PTI 6-PE - 3213966

accessories

MPS-MT - 0201744



PAI-4-FIX BU - 3032729



PAI-4-FIX OG - 3034455



PAI-4-FIX YE - 3032745



PAI-4-FIX RD - 3032732



PAI-4-FIX GN - 3032758



Installation terminal block - PTI 6-PE - 3213966

accessories

PAI-4-FIX BK - 3032774



PAI-4-FIX GY - 3032790



PAI-4-FIX VT - 3032761



PAI-4-FIX BN - 3032787



PS-8 - 3031005



Installation terminal block - PTI 6-PE - 3213966

accessories

PS-8/2,3MM RD - 3048564



Insulating sleeve

MPS-IH WH - 0201663



MPS-IH RD - 0201676



MPS-IH BU - 0201689



MPS-IH YE - 0201692



Installation terminal block - PTI 6-PE - 3213966

accessories

MPS-IH GN - 0201702



MPS-IH GY - 0201728



MPS-IH BK - 0201731



Planning and marking software

CLIP-PROJECT ADVANCED - 5146040



CLIP-PROJECT PROFESSIONAL - 5146053



End block

Installation terminal block - PTI 6-PE - 3213966

accessories

E/UK - 1201442



E/UK 1 - 1201413



CLIPFIX 35 - 3022218



CLIPFIX 35-5 - 3022276




E/NS 35 N - 0800886



Drawings

Installation terminal block - PTI 6-PE - 3213966

Circuit diagram

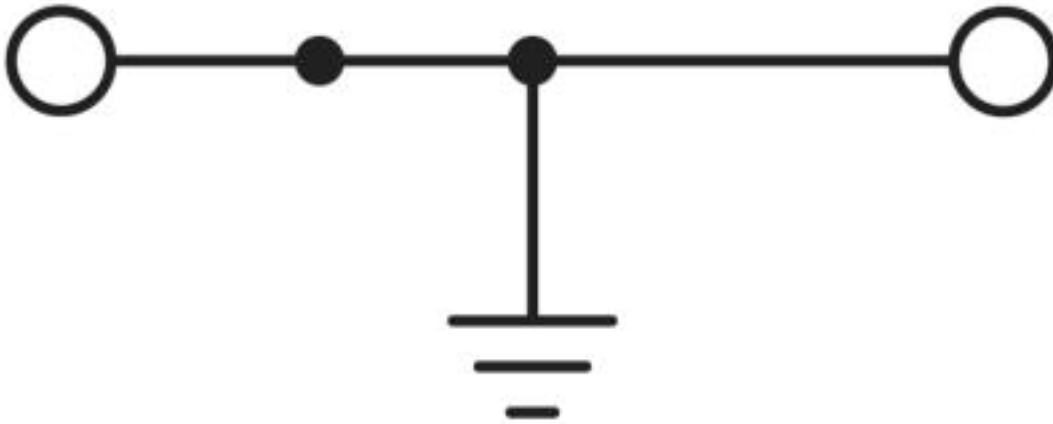

© Phoenix Contact 2013 - all rights reserved
<http://www.phoenixcontact.com>