


TECHNICAL SPECIFICATIONS

- Material:** Polyamid, UL-recognised
- Operating Temperature:** -55°C to +110°C
- Cable Entry:** Top
- Thumbscrews:** UNC 4-40 (Standard)
M2,5 or M3 on request
- Cable O.D:** Up to 11,5mm
- Accessories:** See page XXX
- Assembly Instruction:** See page XXX

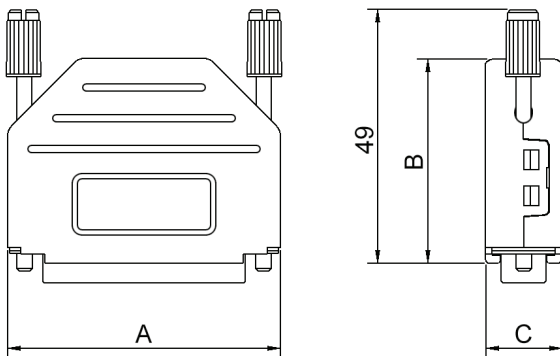

| Size | Dim A | Dim B | Dim C |
|--------|-------|-------|-------|
| 9-way | 31,5 | 34,0 | 15,0 |
| 15-way | 40,0 | 34,0 | 15,0 |
| 25-way | 53,5 | 34,0 | 15,0 |
| 37-way | 70,0 | 40,0 | 15,0 |
| 50-way | 67,5 | 40,0 | 15,0 |

Features:

- Available in sizes 9-15-25-37-50-way
- Suitable for any common Sub-D connector
- Quick-snap locking system
- Standard Colour Black, other colour on request
- Company logo can be moulded on request

Ordering information: Standard - Black

| Size: | P/N - Kitted: | Product Code: |
|--------|---------------|---------------|
| 9-way | 6260-0101-01 | MHDPPK09-BK-K |
| 15-way | 6260-0101-02 | MHDPPK15-BK-K |
| 25-way | 6260-0101-03 | MHDPPK25-BK-K |
| 37-way | 6260-0101-04 | MHDPPK37-BK-K |
| 50-way | 6260-0101-05 | MHDPPK50-BK-K |

| Size: | P/N - BULK: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6261-0101-01 | MHDPPK09-BK |
| 15-way | 6261-0101-02 | MHDPPK15-BK |
| 25-way | 6261-0101-03 | MHDPPK25-BK |
| 37-way | 6261-0101-04 | MHDPPK37-BK |
| 50-way | 6261-0101-05 | MHDPPK50-BK |

Ordering information:



Light Grey

| Size: | Part Number: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6353-0101-01 | MHDPPK09-LG-K |
| 15-way | 6353-0101-02 | MHDPPK15-LG-K |
| 25-way | 6353-0101-03 | MHDPPK25-LG-K |
| 37-way | 6353-0101-04 | MHDPPK37-LG-K |
| 50-way | 6353-0101-05 | MHDPPK50-LG-K |

| Size: | Part Number: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6354-0101-01 | MHDPPK09-LG |
| 15-way | 6354-0101-02 | MHDPPK15-LG |
| 25-way | 6354-0101-03 | MHDPPK25-LG |
| 37-way | 6354-0101-04 | MHDPPK37-LG |
| 50-way | 6354-0101-05 | MHDPPK50-LG |



DEC Grey

| Size: | Part Number: | Product Code: |
|--------|--------------|----------------|
| 9-way | 6353-0102-01 | MHDPPK09-DEC-K |
| 15-way | 6353-0102-02 | MHDPPK15-DEC-K |
| 25-way | 6353-0102-03 | MHDPPK25-DEC-K |
| 37-way | 6353-0102-04 | MHDPPK37-DEC-K |
| 50-way | 6353-0102-05 | MHDPPK50-DEC-K |

| Size: | Part Number: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6354-0102-01 | MHDPPK09-DEC |
| 15-way | 6354-0102-02 | MHDPPK15-DEC |
| 25-way | 6354-0102-03 | MHDPPK25-DEC |
| 37-way | 6354-0102-04 | MHDPPK37-DEC |
| 50-way | 6354-0102-05 | MHDPPK50-DEC |



Red

| Size: | Part Number: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6353-0103-01 | MHDPPK09-R-K |
| 15-way | 6353-0103-02 | MHDPPK15-R-K |
| 25-way | 6353-0103-03 | MHDPPK25-R-K |
| 37-way | 6353-0103-04 | MHDPPK37-R-K |
| 50-way | 6353-0103-05 | MHDPPK50-R-K |

| Size: | Part Number: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6354-0103-01 | MHDPPK09-R |
| 15-way | 6354-0103-02 | MHDPPK15-R |
| 25-way | 6354-0103-03 | MHDPPK25-R |
| 37-way | 6354-0103-04 | MHDPPK37-R |
| 50-way | 6354-0103-05 | MHDPPK50-R |



Blue

| Size: | Part Number: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6353-0104-01 | MHDPPK09-B-K |
| 15-way | 6353-0104-02 | MHDPPK15-B-K |
| 25-way | 6353-0104-03 | MHDPPK25-B-K |
| 37-way | 6353-0104-04 | MHDPPK37-B-K |
| 50-way | 6353-0104-05 | MHDPPK50-B-K |

| Size: | Part Number: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6354-0104-01 | MHDPPK09-B |
| 15-way | 6354-0104-02 | MHDPPK15-B |
| 25-way | 6354-0104-03 | MHDPPK25-B |
| 37-way | 6354-0104-04 | MHDPPK37-B |
| 50-way | 6354-0104-05 | MHDPPK50-B |



Yellow

| Size: | Part Number: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6353-0105-01 | MHDPPK09-Y-K |
| 15-way | 6353-0105-02 | MHDPPK15-Y-K |
| 25-way | 6353-0105-03 | MHDPPK25-Y-K |
| 37-way | 6353-0105-04 | MHDPPK37-Y-K |
| 50-way | 6353-0105-05 | MHDPPK50-Y-K |

| Size: | Part Number: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6354-0105-01 | MHDPPK09-Y |
| 15-way | 6354-0105-02 | MHDPPK15-Y |
| 25-way | 6354-0105-03 | MHDPPK25-Y |
| 37-way | 6354-0105-04 | MHDPPK37-Y |
| 50-way | 6354-0105-05 | MHDPPK50-Y |



Green

| Size: | Part Number: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6353-0106-01 | MHDPPK09-G-K |
| 15-way | 6353-0106-02 | MHDPPK15-G-K |
| 25-way | 6353-0106-03 | MHDPPK25-G-K |
| 37-way | 6353-0106-04 | MHDPPK37-G-K |
| 50-way | 6353-0106-05 | MHDPPK50-G-K |

| Size: | Part Number: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6354-0106-01 | MHDPPK09-G |
| 15-way | 6354-0106-02 | MHDPPK15-G |
| 25-way | 6354-0106-03 | MHDPPK25-G |
| 37-way | 6354-0106-04 | MHDPPK37-G |
| 50-way | 6354-0106-05 | MHDPPK50-G |



White

| Size: | Part Number: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6353-0107-01 | MHDPPK09-W-K |
| 15-way | 6353-0107-02 | MHDPPK15-W-K |
| 25-way | 6353-0107-03 | MHDPPK25-W-K |
| 37-way | 6353-0107-04 | MHDPPK37-W-K |
| 50-way | 6353-0107-05 | MHDPPK50-W-K |

| Size: | Part Number: | Product Code: |
|--------|--------------|---------------|
| 9-way | 6354-0107-01 | MHDPPK09-W |
| 15-way | 6354-0107-02 | MHDPPK15-W |
| 25-way | 6354-0107-03 | MHDPPK25-W |
| 37-way | 6354-0107-04 | MHDPPK37-W |
| 50-way | 6354-0107-05 | MHDPPK50-W |