

**Isolierkörpermaterial**

PBT, UL94V-0

**Kontaktmaterial**

Messing

**Kontaktoberfläche**

Ni, Au / Sn

**Kontaktwiderstand**

20mΩ max

**Isolationswiderstand**

1000MΩ min

**Strombelastbarkeit**

3A

**Betriebstemperatur**

-40°C - +105°C

**Betriebsspannung**

250V AC

**Prüfspannung**

1000V AC

**Verpackung**

Blisterverpackung

**Insulator material**

PBT, UL94V-0

**Contact material**

Brass

**Plating**

Ni, Au / Sn

**Contact resistance**

20mΩ max

**Insulation resistance**

1000mΩ min

**Current rating**

3A

**Operating temperature**

-40°C to +105°C

**Operating voltage**

250V AC

 

**Test voltage**

1000V AC

**Packing**

Tray packing

Dimensions		
No. of contacts	A	B
10	10.16	20.32
14	15.24	25.40
16	17.78	27.94
20	22.86	33.02
26	30.48	40.64
34	40.64	50.80
40	48.26	58.42
50	60.96	71.12
60	73.66	83.82
64	78.74	88.90

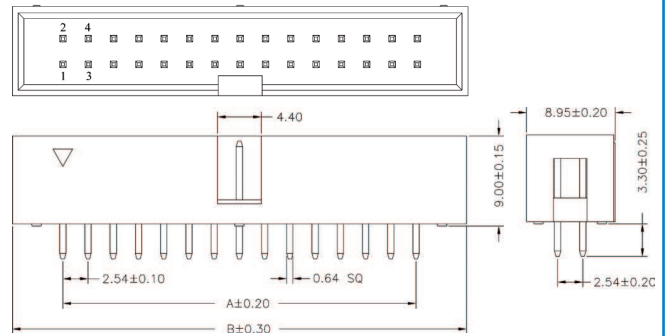

**Bestellcode / Ordercode**

**Polzahl**

10 / 14 / 16 / 20 /  
26 / 34 / 40 / 50 / 60 / 64

**No. of contacts**

10 / 14 / 16 / 20 /  
26 / 34 / 40 / 50 / 60 / 64

**Beschichtung**

5 - vollverzinkt  
2 - Gold flash (selectiv)

**Plating**

5 - Tinned  
2 - Gold flash (selective)

**AWHW xx G - 0 x 0 2 - T**

Bitte „x“ durch die geeignete Option ersetzen  
Please replace „x“ with appropriate option

D-Sub /  
Centronics

Multiflex -  
DIN 41651

Modular

USB  
IEEE 1394

Switches

Powerinlets  
Poweroutlets

DIN 41612  
DIN 41617  
Hard Metric

MiniDIN

Pin header  
Female header  
Sockets / Jumper

Terminal Blocks

Memory Card  
connectors

FFC / FPC

Micro -  
Miniature