


TECHNICAL SPECIFICATIONS

- Material:** Zinc, Black
- Operating Temperature:** -40°C to +120°C
- Cable Entry:** 45° Side Entry
- Thumbscrews:** UNC 4-40 (Standard)
M2,5 or M3 on request
- Cable O.D.:** Up to 13mm
- Accessories:** See page 186-190
- Assembly Instruction:** See page 197




Features:

- Available in sizes 9-15-25-37
- Excellent EMI Shielding
- Strain relief inserts ensure a secure termination

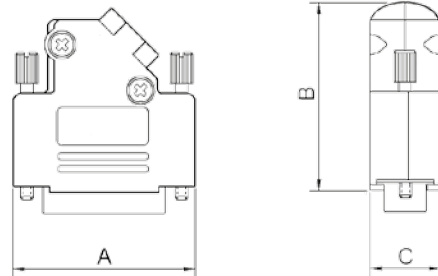

Size MHD45ZK	Dim A	Dim B	Dim C
9-way	31,0	36,3	14,5
15-way	39,5	40,3	14,5
25-way	53,2	40,3	14,5
37-way	69,7	40,3	14,5

Grommet Sizes / D45ZK09-37:

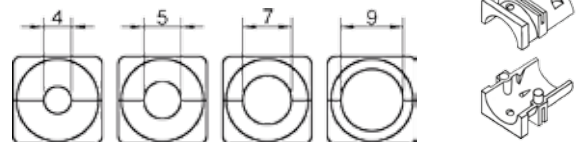

Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	6560-0116-11	MHD45ZK-9-BK-K
15-way	6560-0116-12	MHD45ZK-15-BK-K
25-way	6560-0116-13	MHD45ZK-25-BK-K
37-way	6560-0116-14	MHD45ZK-37-BK-K

Size:	P/N - BULK:	Product Code:
9-way	6561-0116-11	MHD45ZK-9-BK
15-way	6561-0116-12	MHD45ZK-15-BK
25-way	6561-0116-13	MHD45ZK-25-BK
37-way	6561-0116-14	MHD45ZK-37-BK