


## TECHNICAL SPECIFICATIONS

<b>Material:</b>	UL recognised Plastic Material
<b>Plating:</b>	Nickel over Copper
<b>Operating Temperature:</b>	-40°C to +120°C
<b>Cable Entry:</b>	Top Entry
<b>Thumbscrews:</b>	UNC 4-40 (Short)
<b>Cable O.D.:</b>	Up to 13mm

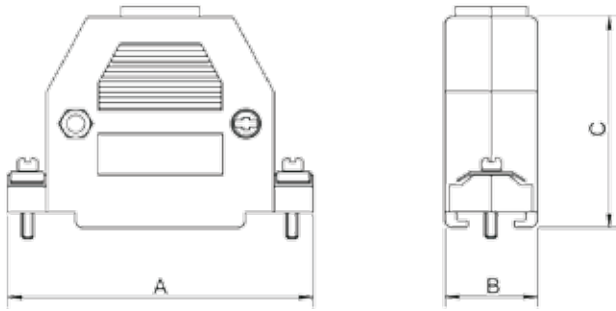

Size	Dim A	Dim B	Dim C
9-way	31,0	16,0	40,2
15-way	39,6	17,4	38,0
25-way	55,0	16,5	44,5
37-way	69,0	24,0	52,5
50-way	69,5	19,5	44,5

### Features:

- Available in sizes 9-15-25-37-50
- Re-openable
- Also available in Unshielded version, See page 13

### Ordering information: *Short Jackscrews*

Size:	P/N - Kitted:	Product Code:
9-way	2360-0105-01	MHCCOV 9-SC-MP
15-way	2360-0105-02	MHCCOV15-SC-MP
25-way	2360-0105-03	MHCCOV25-SC-MP
37-way	2360-0105-04	MHCCOV37-SC-MP
50-way	2360-0105-05	MHCCOV50-SC-MP

### *Long Jackscrews*

Size:	P/N - Kitted:	Product Code:
9-way	2360-0105-11	MHCCOV 9-SCL-MP
15-way	2360-0105-12	MHCCOV15-SCL-MP
25-way	2360-0105-13	MHCCOV25-SCL-MP
37-way	2360-0105-14	MHCCOV37-SCL-MP
50-way	2360-0105-15	MHCCOV50-SCL-MP