


<b>Description</b>		OD: 6.0*4.2mm [ID: 3.7 (1/0.8CCS) *1C+AL+B (16/6/0.10CCS)]*1F+[ID: 1.6 (7/0.30BS) *2C]*1F	
<b>Content</b>		A: 1C	B: 2C
<b>Conductor</b>	Structure	1/0.8 ± 0.008CCS	7/0.30 ± 0.008BS
	External diameter	0.8	0.91
	Material	PE	PP
<b>Insulation</b>	External diameter	3.7 ± 0.1mm	1.6 ± 0.1mm
	Color	mutural	natural grey
<b>Belting</b>	Name	aluminum foil	
	Specification	15mm aluminum foil / pitch 0.025mm	
<b>Braid</b>	Specification	16/6/0.10CCS	
	Pitch	33.47 ± 1mm	
	External diameter	4.2	
<b>Jacket</b>	Color	55P white PVC	
	External diameter	6.0 ± 0.15mm+4.2 ± 0.15mm	

Picture:

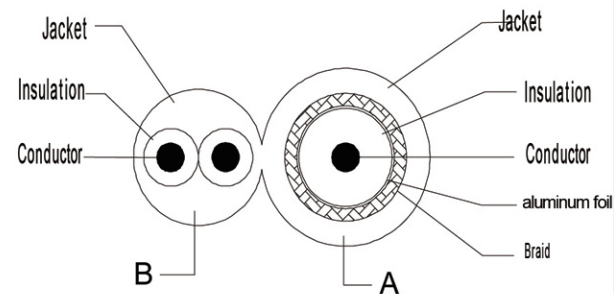

**Inspection standards**

electric persistence	coaxial 75	$\Omega \pm 5$
on resistance	$\leq 5$	$\Omega$
insulation resistance	$\geq 5$	M $\Omega$ DC300V
Corewire EDM	1.50	KV
Cuticle EDM	3.00	KV
Withstand Voltage	AC 300	V/1 Min
Anti-electricity level	Q/QYY02- new version	

product No	754300
product Name	CCTV Cable
Drawn' d/Date	2012.7.22

**Packing**



With PE shrink

Picture:

10070+50-0

