


| Description | | OD: 6.0*4.2mm[ID: 3.7 (1/0.8CCS) *1C+AL+B (16/6/0.10CCS)]*1F+[ID: 1.6 (7/0.30BS) *2C]*1F | |
|-------------|-------------------|--|------------------|
| Content | | A: 1C | B: 2C |
| Conductor | Structure | 1/0.8 ± 0.008CCS | 7/0.30 ± 0.008BS |
| | External diameter | 0.8 | 0.91 |
| | Material | PE | PP |
| Insulation | External diameter | 3.7 ± 0.1mm | 1.6 ± 0.1mm |
| | Color | mutural | natural grey |
| Belting | Name | aluminum foil | |
| | Specification | 15mm aluminum foil / pitch 0.025mm | |
| Braid | Specification | 16/6/0.10CCS | |
| | Pitch | 33.47 ± 1mm | |
| | External diameter | 4.2 | |
| Jacket | Color | 55P white PVC | |
| | External diameter | 6.0 ± 0.15mm+4.2 ± 0.15mm | |

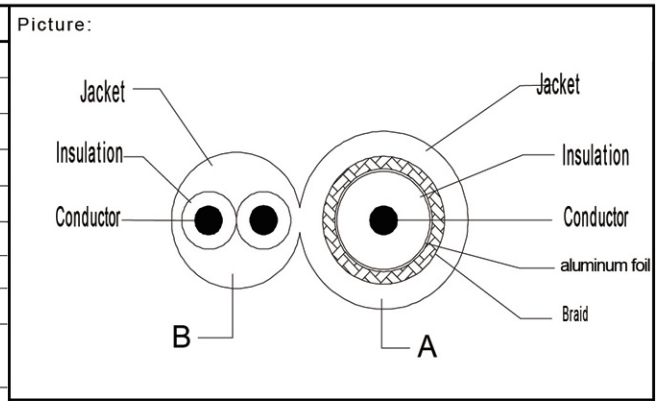

| Inspection standards | | |
|------------------------|----------------------|-------------------|
| electric persistence | coaxial 75 | $\Omega \pm 5$ |
| on resistance | ≤ 5 | Ω |
| insulation resistance | ≥ 5 | M Ω DC300V |
| Corewire EDM | 1.50 | KV |
| Cuticle EDM | 3.00 | KV |
| Withstand Voltage | AC 300 | V/1 Min |
| Anti-electricity level | Q/QYY02- new version | |
| product No | 754306 | |
| product Name | CCTV Cable | |
| Drawn' d/Date | 2012.7.22 | |

