


**Maßtabelle für Blockgewichte**

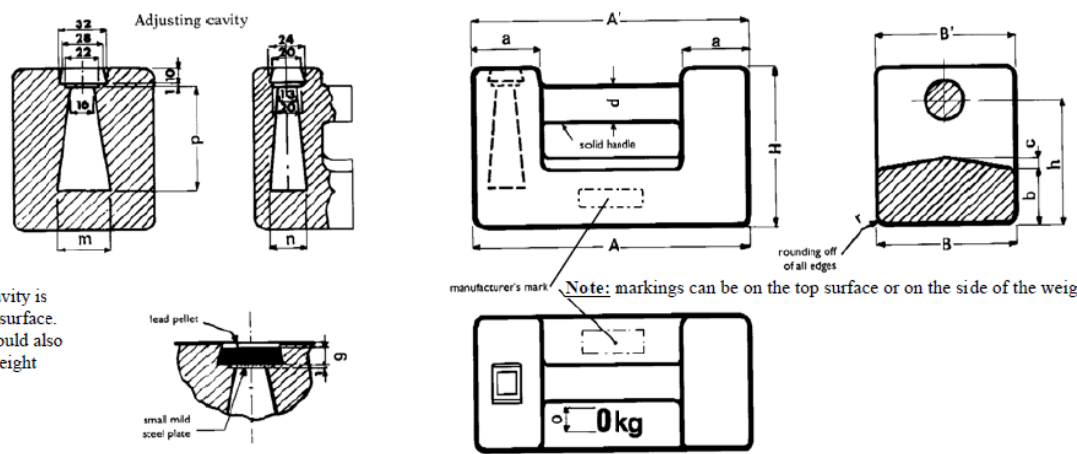

**Note:** The adjusting cavity is shown here on the top surface. The adjusting cavity could also be on the side of the weight

**Note:** markings can be on the top surface or on the side of the weight

A.3 Rectangular bar weights (Type 2)  
Table of dimensions (in millimeters)

Nominal Value	A	A'	B	B'	H	a	b	c	h	d	r	o	m	n	p
5 kg	150	152	75	77	84	36	30	6	66	19	5	12	16	13	55
10 kg	190	193	95	97	109	46	38	8	84	25	6	16	35	25	70
20 kg	230	234	115	117	139	61	52	12	109	29	8	20	50	30	95
50 kg	310	314	155	157	192	83	74	16	152	40	10	25	70	40	148

Dimensions A and A' as well as B and B' can be reversed  
Toleranz: ±5%