


SAUTER AC 03

Screw Tension Clamp for tension tests

KERN

Pictograms

STANDARD

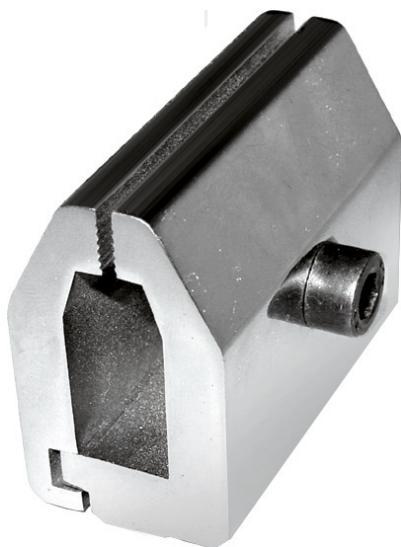

Category

Brand	Sauter
Product category	Clamp
Product group	Screw tension clamp

Construction

Dimensions completely mounted (W×D×H)	50×41×34 mm
Material	steel
Material housing	metal
Mounting - force dissipation	Threaded hole M6
Maximum clamp width	20 mm
Clamping width	4,5 mm
Tensile/compressive force [Max]	5 kN

Environmental conditions

Storage temperature [Min]	-10 °C
Storage temperature [Max]	40 °C

Packing & Shipping

Delivery time	1 d
Dimensions packaging (W×D×H)	150×100×10 mm
Shipping method	Parcel service
Net weight approx.	0,60 kg
Gross weight approx.	0,60 kg
Shipping weight	0,58 kg

Product information

GTIN/EAN number	4045761122314
REACH classification	no prohibited substances