


SAUTER AC 18

KERN

Screw tension clamp with 2 wide jaw grips for tension and extraction tests

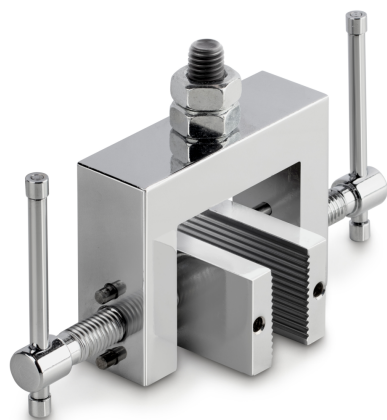

Pictograms

STANDARD



Category

Brand	Sauter
Product category	Clamp
Product group	Screw tension clamp

Construction

Dimensions completely mounted (W×D×H)	160×100×140 mm
Material	steel
Mounting - force dissipation	External thread M10
Maximum clamp width	60 mm
Clamping width	33 mm
Tensile/compressive force [Max]	5 kN

Environmental conditions

Storage temperature [Min]	-10 °C
Storage temperature [Max]	40 °C

Packing & Shipping

Delivery time	1 d
Dimensions packaging (W×D×H)	160×100×140 mm
Shipping method	Parcel service
Net weight approx.	0,75 kg
Gross weight approx.	0,80 kg
Shipping weight	0,753 kg

Product information

GTIN/EAN number	4045761122413
REACH classification	no prohibited substances