


SAUTER FK-A02

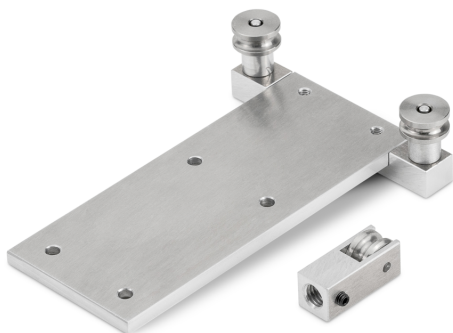

Tensiometer kit for high-capacity tensile strength testing up to 1000 N, steel attachment and steel rolls, rolls cannot be adjusted



Category

Brand	Sauter
Product category	Measurement technology
Product group	Accessories for force measuring device

Construction

Dimensions device (W×D×H)	140×140×40 mm
Dimensions completely mounted (W×D×H)	152×80×28 mm
Material	metal
Material housing	metal

Environmental conditions

Storage temperature [Min]	-10 °C
Storage temperature [Max]	40 °C

Packing & Shipping

Delivery time	1 d
Shipping method	Parcel service
Net weight approx.	0,15 kg
Gross weight approx.	0,15 kg
Shipping weight	0,133 kg

Product information

GTIN/EAN number	4045761138667
REACH classification	no prohibited substances

Pictograms

STANDARD

