


KERN FOB3K1

Edelstahlwaage mit erhöhtem Feuchteschutz und Eichzulassung [M]

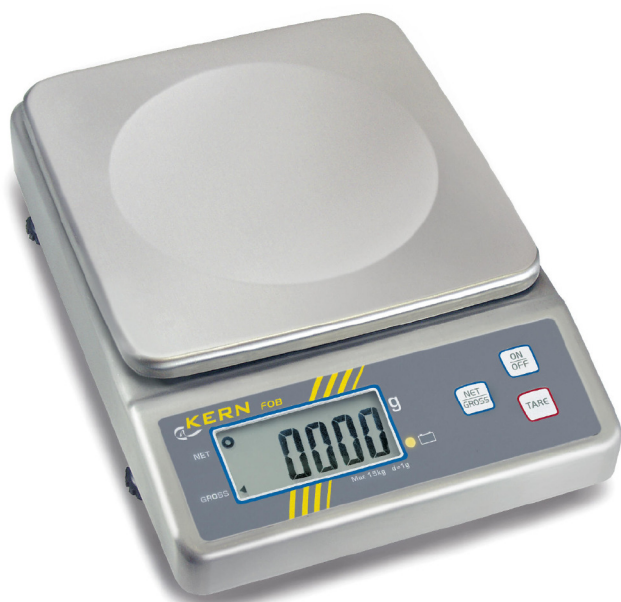

Service

Adjustment at the location of installation: 961-247

DAkkS Certificate: 963-127

Category

Brand: KERN

Category: Balances

Product Group: Bench scale

Packaging & shipping

Delivery: 24 h

Dimensions packaging (WxDxH): 400 x 250 x 110 mm

Gross weight: 2,616 kg

Net weight: 2,135 kg

Shipping method: Parcel service

Construction

Casing material: stainless steel

Dimensions housing (WxDxH): 175 x 240 x 60 mm

Level indicator: yes

Material weighing plate: stainless steel

Revolving screw feet: yes

Weighing surface (WxD): 175 x 165 mm

Measuring system

Adjustment options: External calibration

Linearity: 2 g

Readout [d]: 1 g

Recommended adjusting weight: 2 kg (M3)

Reproducibility: 1 g

Resolution: 3000

Stabilisation time: 2 s

Warm up time: 10 min

Weighing range [Max]: 3 kg

Weighing system: Strain gauge

Weighing units: g lb oz

Display

Display digit height: 2,500 cm

Environmental conditions

Maximum humidity: 95 %

Maximum operating temperature: 40 °C

Minimum ambient temperature: -10 °C

Minimum humidity: 25 %

Power supply

Charging time: 8 h

n/a: CH EURO

Operating time (Backlight off): 24 h

Rechargeable battery: Rchrg. battery optional